

RMI 24V AC/DC OUTPUT RELAY


IN: 24 VAC/DC - OUT: 250 VAC/DC / 8 A

Link do produto

Ilustração



Produto pode diferir da imagem

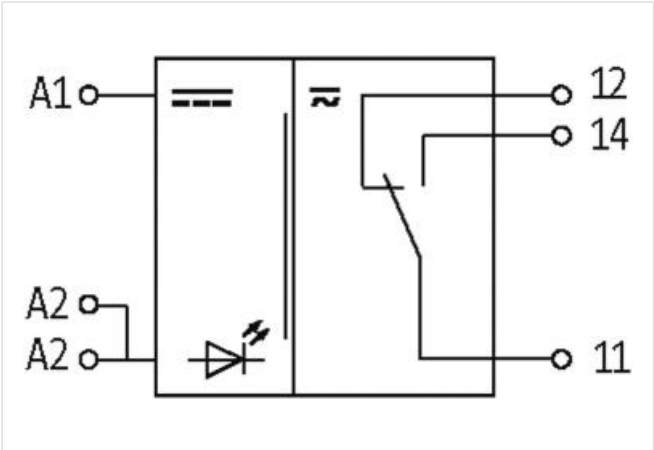

Dados comerciais

ECLASS-6.0	27371001
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-8.0	27371601
ECLASS-9.0	27371601
ECLASS-10.1	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ETIM-5.0	EC001437
Classificação fiscal	85364900
GTIN	4048879027427
Quantidade por embalagem	1

Electrical data | Output

Utilization category AC-15 (EN IEC 60947-5-1)	3 A @ 24 V, 3 A @ 110 V, 3 A @ 230 V
Utilization category DC-13 (EN IEC 60947-5-1)	1,5 A @ 24 V, 0,3 A @ 110 V, 0,15 A @ 230 V
Switching capacity AC-12 (EN IEC 60947-5-1)	8 A (24/110/230 V AC)

Connection type 2

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	3
PIN 1	A 2

PIN 2	A 2
PIN 3	A 1
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	3
PIN 1	12
PIN 2	11
PIN 3	14