

UFL 34 L PLUG FOR SIGNAL TRANSFER

24 VDC / 1 A - male with LED




Ribbon cable connector + LED

34-pole


Via the combined fixing mechanism, connectors with or without strain relief can be connected.
for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

Link do produto

Ilustração

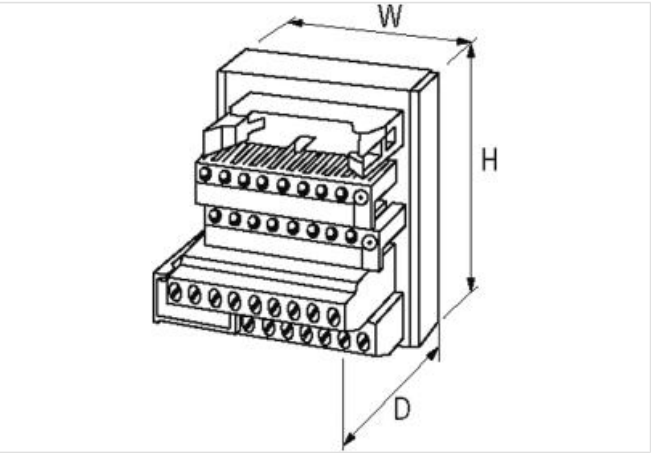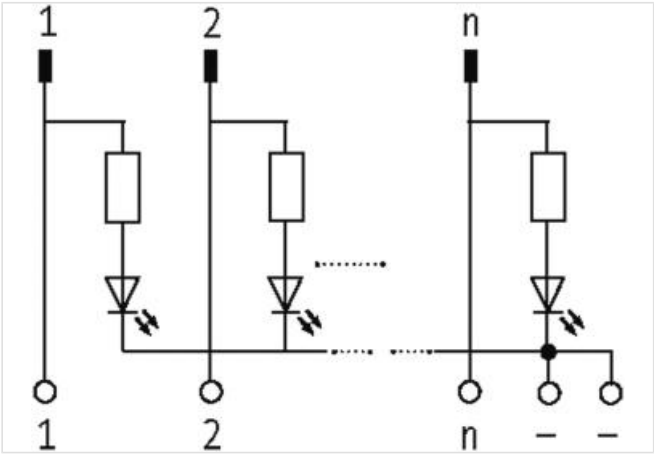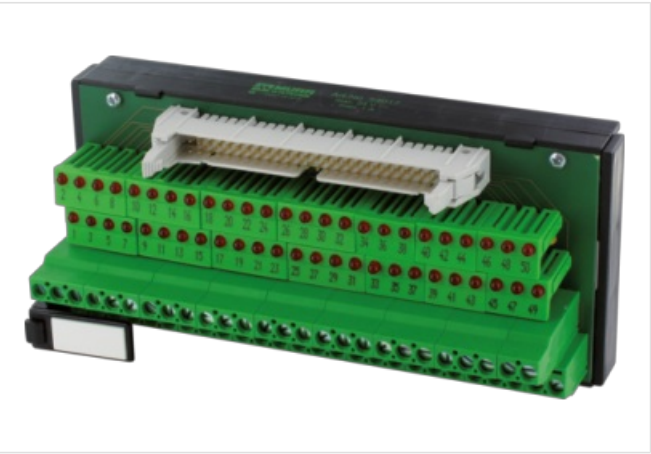

Produto pode diferir da imagem

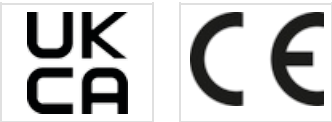

Dados comerciais	
ECLASS-6.0	27141120
ECLASS-6.1	27141120
ECLASS-7.0	27141120
ECLASS-8.0	27141120
ECLASS-9.0	27141120

ECLASS-10.1	27141120
ECLASS-11.1	27141120
ECLASS-12.0	27141120
ETIM-5.0	EC001283
Classificação fiscal	85366990
GTIN	4048879026581
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC	24 V
Operating current max.	1 A
Diagnostics	
Status indication LED	red
Device protection Electrical	
Overvoltage category (EN 60664-1)	II
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	95 mm
Depth	48 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C