



**PKB 1 FOR SIGNAL TRANSFER**

250V / 15 A

4x 22-pole  
 15 A per potential rail  
 Screw plug-in terminals

[Link do produto](#)

**Ilustração**

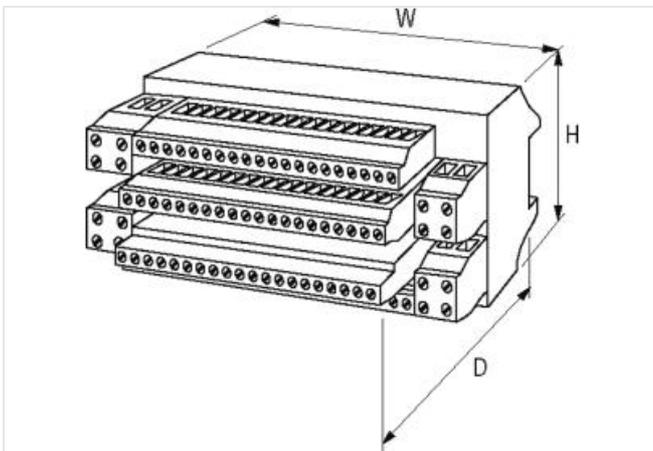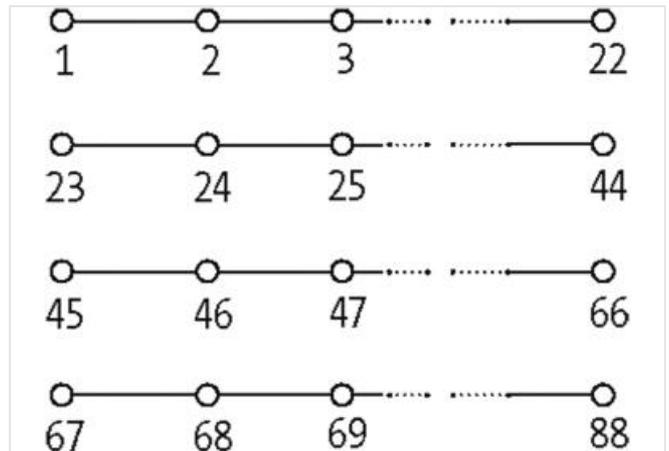

Produto pode diferir da imagem



**Dados comerciais**

ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado. A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 19/04/2024

ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
Classificação fiscal	85369010
GTIN	4048879026062
Quantidade por embalagem	1

**Electrical data | Supply**

Operating voltage AC	250 V
Total current per potential rail max.	15 A

**Installation**

Connection cross-section solid max.	4 mm <sup>2</sup>
-------------------------------------	-------------------

**Installation | Connection**

Connection	Screw terminals SK
------------	--------------------

**Device protection | Electrical**

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

**Mechanical data | Mounting data**

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	140 mm
Depth	48 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C