

CUBE20S POWER MODULE

24VDC


Power module
Expansion module
for external voltage supply

Link do produto

Ilustração



Produto pode diferir da imagem

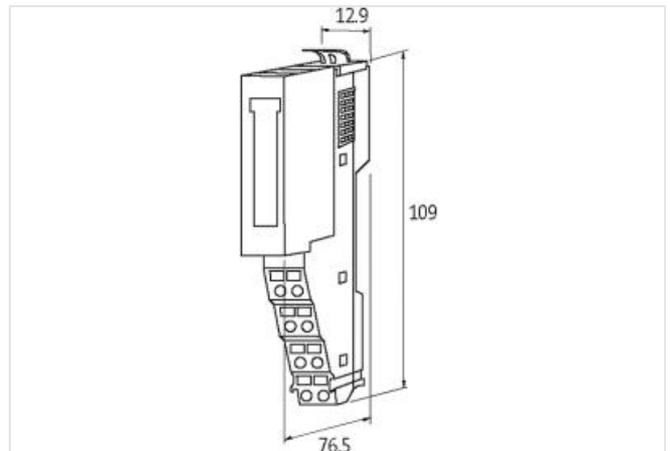

Dados comerciais

ECLASS-6.0	27242610
ECLASS-6.1	27242611
ECLASS-7.0	27242611
ECLASS-8.0	27242611
ECLASS-9.0	27242611
ECLASS-10.1	27242611
ECLASS-11.1	27242611
ECLASS-12.0	27242611
ETIM-5.0	EC001600
Classificação fiscal	85369010
GTIN	4048879422888
Quantidade por embalagem	1

Electrical data | Supply

Operating voltage DC	24 V
Total current max.	10 A

Electrical data | Input

Input voltage DC	24 V
Input voltage DC min.	20,4 V
Input voltage DC max.	28,8 V

Electrical data | Output

Output voltage DC	24 V
Output current	10 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	109 mm
Width	12,9 mm
Depth	76,5 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C
Connection type 1	
Connection type 1	Power
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys