

CUBE20S SSI MODULE

SSI Encoder


RS422

Link do produto

Ilustração



Produto pode diferir da imagem

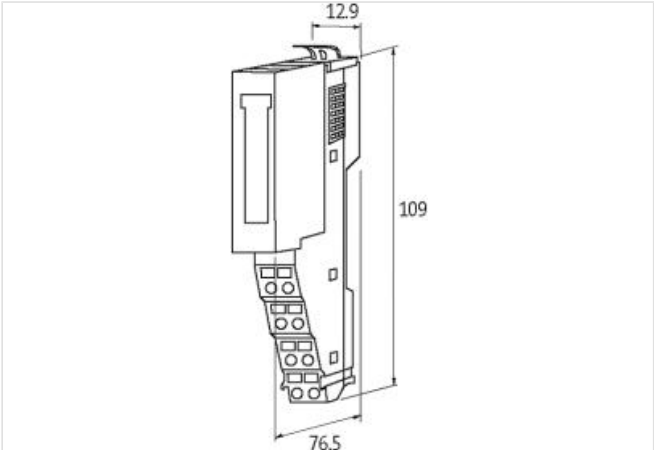

Dados comerciais	
ECLASS-6.0	27242605
ECLASS-7.0	27242605
ECLASS-8.0	27242605
ECLASS-9.0	27242605
ETIM-5.0	EC001601
Classificação fiscal	85389099
GTIN	4048879422925
Quantidade por embalagem	1
Electrical data Supply	
Current consumption max.	70 mA
module supply	via system connection
Diagnostics	
Diagnostic	Under voltage
Diagnostic via BUS	per module
Diagnostic via LED	per module and channel
Short circuit diagnosis	yes
LED display	Ethernet connection/data traffic
Overload diagnosis	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Mounting data	
Mounting method	geschnappt

Suitable for mounting type	mounting rail, (EN 60715)
Height	109 mm
Width	12,9 mm
Depth	76,5 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	70 °C

Connection type 2

Connection type 1	Power
Connection type 2	Power
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	n.c.
PIN 2	24 V DC
PIN 3	0 V
PIN 4	24 V DC Sys
PIN 5	n.c.
PIN 6	24 V DC
PIN 7	0 V
PIN 8	0 V Sys
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	8
PIN 1	CO +
PIN 2	24 V DC
PIN 3	0 V
PIN 4	CI +
PIN 5	CO -
PIN 6	DI +
PIN 7	DI -
PIN 8	CI -