


Xelity 8TX Unmanaged Switch 8 Port 100Mbit

8 port unmanaged switch
Connection cables are in the online shop under "Connection Technology".

Link do produto

Ilustração

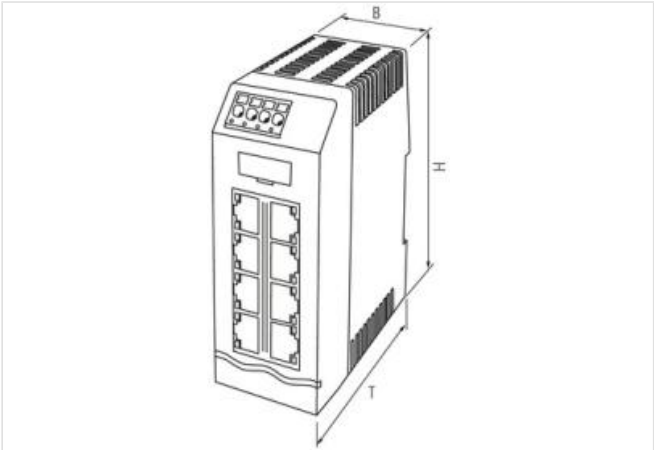

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	19170106
ECLASS-6.1	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170106
ECLASS-10.1	19170402
ECLASS-11.1	19170402
ECLASS-12.0	19170402
ETIM-5.0	EC000734
Classificação fiscal	85176200
GTIN	4048879798808
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC min.	9,5 V
Operating voltage DC max.	31,5 V
Power consumption max.	1,2 W
Current consumption max.	50 mA
Industrial communication	
Data transmission rate max.	100 MBit/s
Industrial communication Ethernet functionality	
Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex

Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes
Diagnostics	
Alarm contact	no
Diagnostic	No voltage
LED display	Ethernet connection/data traffic
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Invers-polarity protection	yes
Over voltage protection	yes
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	105 mm
Width	41,6 mm
Depth	85,1 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C
Connection type 2	
Connection type 1	8
Family construction form	RJ45
Gender	female
Color contact carrier	black
No. of poles	8
PIN 1	TD +
PIN 2	TD -
PIN 3	RD +
PIN 4	n.c.
PIN 5	n.c.
PIN 6	RD -
PIN 7	n.c.
PIN 8	n.c.
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	24 V DC (UB 1)
PIN 2	0 V
PIN 3	PE
PIN 4	n.c.