

Xenterra 8TX unmanaged Switch 8 Port 1000Mbit wall mounting


8 Port Unamanged IP20 Gigabit Switch
Wall mounting

Link do produto

Ilustração



Produto pode diferir da imagem

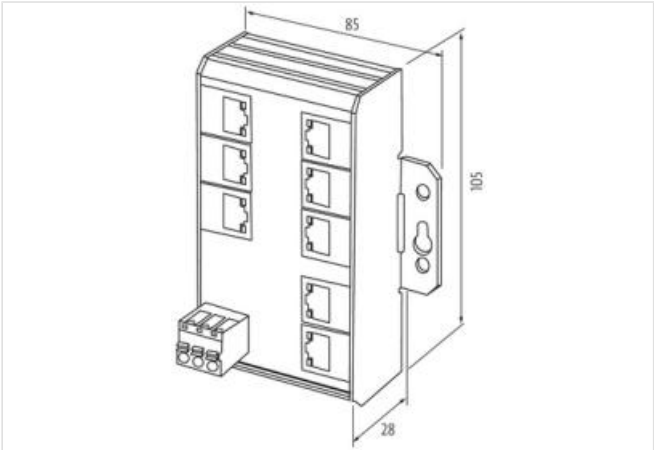

Dados comerciais	
ECLASS-6.1	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170402
ECLASS-10.1	19170402
ECLASS-11.1	19170402
ECLASS-12.0	19170402
Classificação fiscal	85176200
GTIN	4048879873550
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC min.	8 V
Operating voltage AC max.	28 V
Operating voltage DC min.	9 V
Operating voltage DC max.	36 V
Industrial communication	
Data transmission rate max.	1000 MBit/s
Industrial communication Ethernet functionality	
Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes

Diagnostics	
Alarm contact	no
Diagnostic	No voltage
LED display	Ethernet connection/data traffic
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Material data	
Color housing	black
Material housing	Metal
Mechanical data Mounting data	
Mounting method	screwed
Suitable for mounting type	Schlüssellochabhängung
Height	105 mm
Width	85 mm
Depth	28 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C
Connection type 1	
Connection type 1	8
Family construction form	RJ45
Gender	female
Color contact carrier	black
No. of poles	8
PIN 1	TD +
PIN 2	TD -
PIN 3	RD +
PIN 4	n.c.
PIN 5	n.c.
PIN 6	RD -
PIN 7	n.c.
PIN 8	n.c.