



ASSEMBLY MODULE MP 6 S

Mounting rail / screw-type terminal

6 pairs of solder pins
screw terminals connected to solder pin pairs

Link do produto

Ilustração

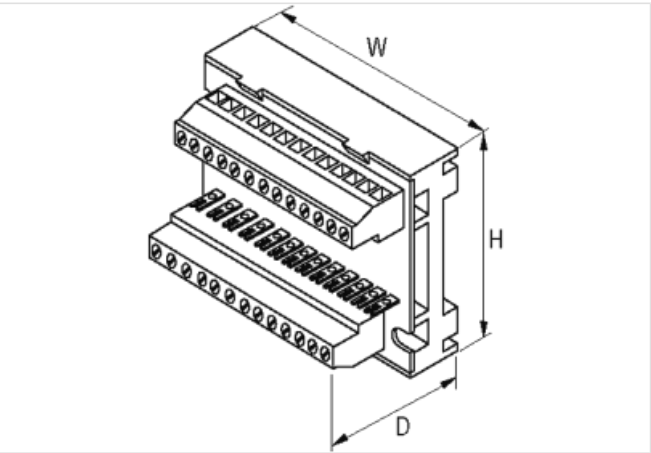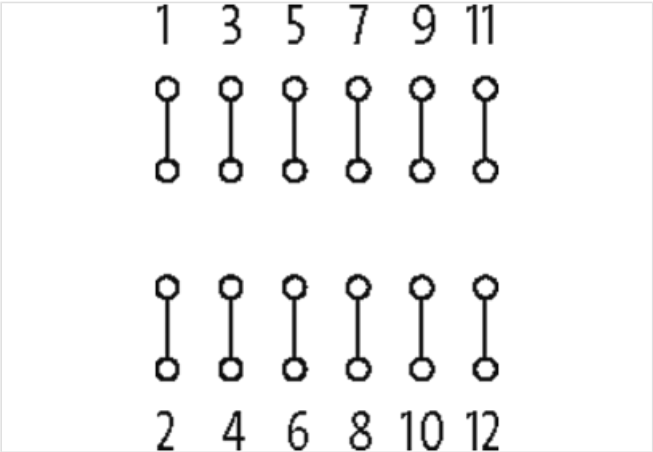

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27260710
ECLASS-6.1	27141149
ECLASS-7.0	27141149
ECLASS-8.0	27141149
ECLASS-9.0	27141149
ECLASS-10.1	27141149
ECLASS-11.1	27141149
ECLASS-12.0	27141149
ETIM-5.0	EC002780
Classificação fiscal	85369010
GTIN	4048879042239
Quantidade por embalagem	1

Electrical data Supply	
Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	5 A
Installation	
Connection cross section max.	4 mm ²
Installation Connection	
Connection	Screw terminals SK
Connection information	Lötstützpunktpaare (Raster 5 mm)
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Housing properties	open design
Material housing	Plastic
Mechanical data Mounting data	
Distance of solder pins	50 mm
Mounting method	screwed, geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	63 mm
Width	90 mm
Depth	36 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C