

## EUROCARD HOLDER

SKP 31/II

Screw terminals

31-pole (DIN 41617)

Connection via double row terminals on one side


With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

### Link do produto

#### Ilustração

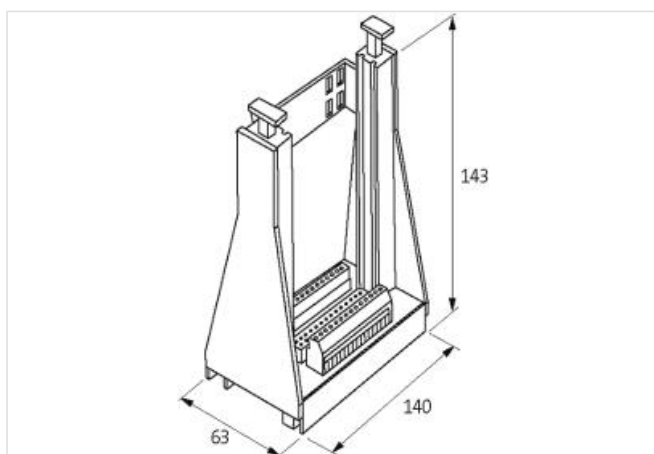

Produto pode diferir da imagem



#### Dados comerciais

|            |          |
|------------|----------|
| ECLASS-6.0 | 27260710 |
| ECLASS-6.1 | 27260704 |
| ECLASS-7.0 | 27440402 |

|                                        |                           |
|----------------------------------------|---------------------------|
| ECLASS-8.0                             | 27440402                  |
| ECLASS-9.0                             | 27460201                  |
| ECLASS-10.1                            | 27440402                  |
| ECLASS-11.1                            | 27460201                  |
| ECLASS-12.0                            | 27460201                  |
| ETIM-5.0                               | EC002780                  |
| Classificação fiscal                   | 85366990                  |
| GTIN                                   | 4048879042208             |
| Quantidade por embalagem               | 1                         |
| <b>Electrical data   Supply</b>        |                           |
| Operating voltage AC                   | 250 V                     |
| Operating current max.                 | 5 A                       |
| <b>Installation</b>                    |                           |
| Connection cross-section solid max.    | 4 mm <sup>2</sup>         |
| <b>Installation   Pin assignment</b>   |                           |
| No. of poles                           | 31                        |
| <b>Device protection   Electrical</b>  |                           |
| Overvoltage category (EN 60664-1)      | I                         |
| <b>Device protection   Media</b>       |                           |
| Flame resistance                       | flame retardant           |
| <b>Mechanical data</b>                 |                           |
| Type of socket connector               | DIN 41617                 |
| <b>Mechanical data   Material data</b> |                           |
| Material housing                       | Plastic                   |
| <b>Mechanical data   Mounting data</b> |                           |
| Mounting method                        | screwed, geschnappt       |
| Suitable for mounting type             | mounting rail, (EN 60715) |
| Height                                 | 137 mm                    |
| Width                                  | 63 mm                     |
| Depth                                  | 170 mm                    |