



MKS - D 10/1300-1 M DIODE MODULES

Mounting rail / screw-type terminal

10 diodes  
Common potential anode

Link do produto

Ilustração

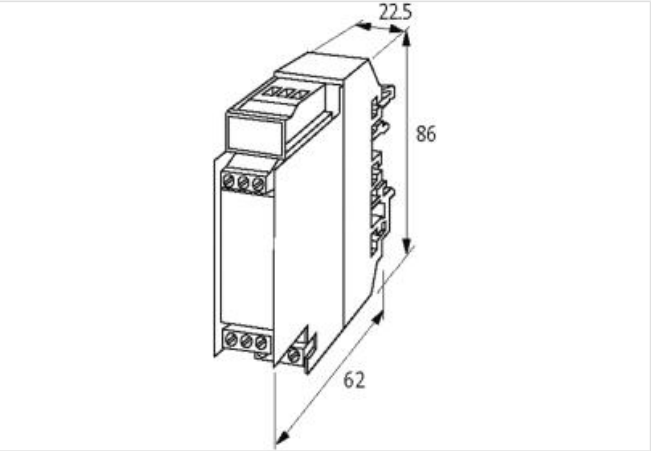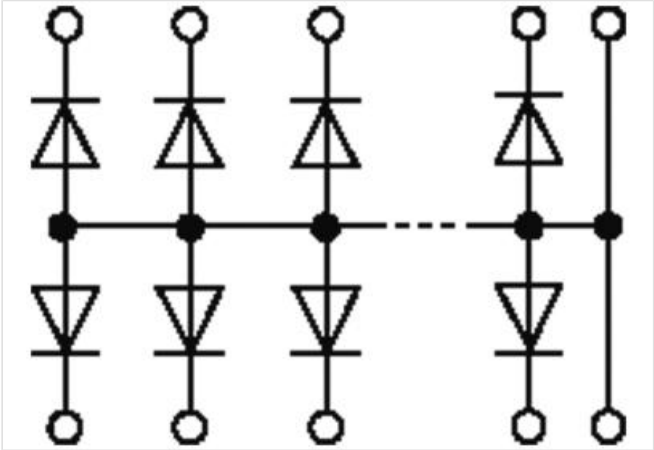

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27371010 |
| ECLASS-6.1       | 27371010 |
| ECLASS-7.0       | 27371010 |
| ECLASS-8.0       | 27371010 |
| ECLASS-9.0       | 27371010 |
| ECLASS-10.1      | 27371010 |
| ECLASS-11.1      | 27371010 |
| ECLASS-12.0      | 27371010 |

|                                                 |                                     |
|-------------------------------------------------|-------------------------------------|
| ETIM-5.0                                        | EC002780                            |
| Classificação fiscal                            | 85411000                            |
| GTIN                                            | 4048879041959                       |
| Quantidade por embalagem                        | 1                                   |
| <b>Electrical data   Supply</b>                 |                                     |
| Operating voltage AC max.                       | 48 V                                |
| Operating voltage DC max.                       | 48 V                                |
| <b>Installation</b>                             |                                     |
| Connection cross section max.                   | 4 mm <sup>2</sup>                   |
| <b>Installation   Connection</b>                |                                     |
| Connection                                      | Screw terminals SK                  |
| <b>Mechanical data   Mounting data</b>          |                                     |
| Mounting method                                 | geschnappt                          |
| Suitable for mounting type                      | Mounting rail TH35, G32, (EN 60715) |
| Height                                          | 86 mm                               |
| Width                                           | 22,5 mm                             |
| Depth                                           | 62 mm                               |
| <b>Environmental characteristics   Climatic</b> |                                     |
| Operating temperature min.                      | -20 °C                              |
| Operating temperature max.                      | 60 °C                               |
| <b>Connection type 1</b>                        |                                     |
| Connection                                      | Screw terminals SK                  |
| Family construction form                        | terminal                            |
| Gender                                          | female                              |
| No. of poles                                    | 12                                  |