



MKS - D 6/1300 - 1 DIODE MODULES

Mounting rail / screw-type terminal

Universal diode 1 300 V, 1 A
6 diodes
separation contact via pluggable jumpers
Diode modules are suitable for the suppression of inductive loads (valve, contactor, etc.)

Link do produto

Ilustração

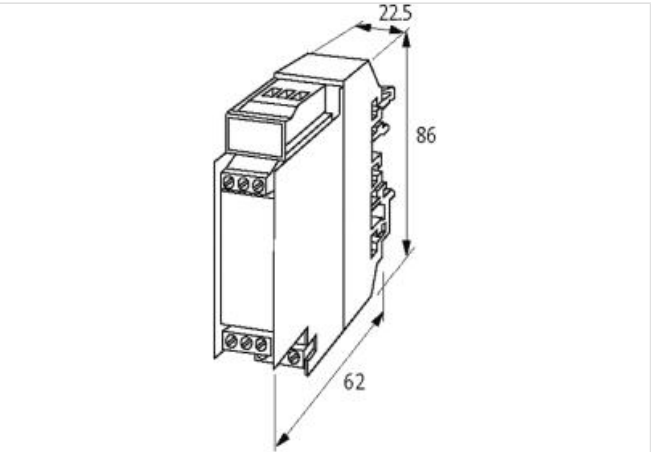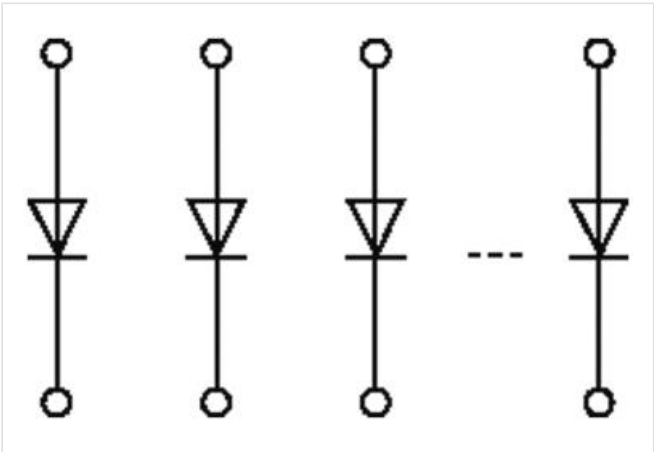

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371010
ECLASS-6.1	27371010
ECLASS-7.0	27371010
ECLASS-8.0	27371010
ECLASS-9.0	27371010
ECLASS-10.1	27371010

ECLASS-11.1	27371010
ECLASS-12.0	27371010
ETIM-5.0	EC002780
Classificação fiscal	85411000
GTIN	4048879041904
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC max.	48 V
Operating voltage DC max.	48 V
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, G32, (EN 60715)
Height	86 mm
Width	22,5 mm
Depth	62 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Connection type 1	
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	12