

HYBRID FIELD-BUS COUPLERS

Conversion electrical-electrical (passive)


CU, CU (female/female)
Han-Brid ® a registered trademark of HARTING KGaA.

Link do produto

Ilustração



Produto pode diferir da imagem

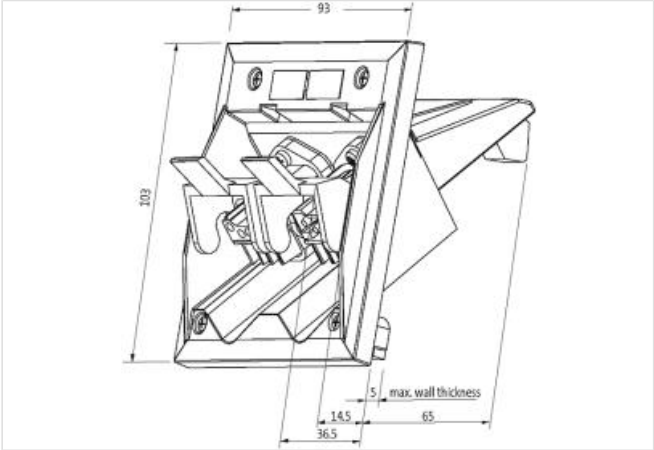

Dados comerciais	
ECLASS-6.0	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27189217
ETIM-5.0	EC002641
Classificação fiscal	85366990
GTIN	4048879041492
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC	24 V
Industrial communication	
Data transmission rate max.	12 MBit/s
Installation	
Connection cross-section solid max.	0,25 mm²
Connection cross-section stranded/fine-stranded max.	2,5 mm²
Installation Connection	
Connection	Spring clamp plug-in terminals
Device protection	
Shielded	no
Device protection Media	

Flame resistance flame retardant

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height cutout	90 mm
Width cutout	80 mm
Height	103 mm
Width	93 mm
Depth	65 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	50 °C