

LED-INDICATOR OPAC / GREEN

LED-110V IP65


(green)
110 V AC/DC
The modules are suitable for wall thickness of 1.5...5.0 mm.

Link do produto

Ilustração



Produto pode diferir da imagem

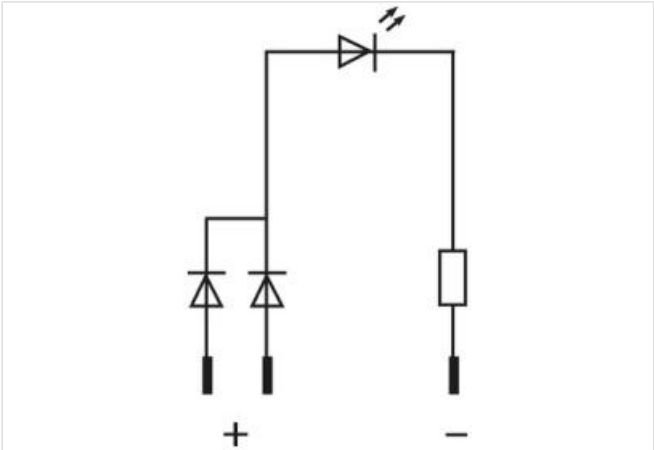

Dados comerciais	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
Classificação fiscal	85318070
GTIN	4048879041263
Quantidade por embalagem	10
Electrical data Supply	
Operating voltage AC	110 V
Operating voltage AC min.	95 V
Operating voltage AC max.	121 V
Operating voltage DC	110 V
Operating voltage DC min.	95 V
Operating voltage DC max.	121 V
Current consumption min.	8 mA
Current consumption max.	12 mA
Installation Connection	
Connection information	Faston 2.8×0.8 mm
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65

Flame resistance flame retardant

Diameter LED	5 mm
--------------	------

Material housing	Plastic
------------------	---------

Diameter front panel drilling	9 mm
-------------------------------	------

Operating temperature min. -20 °C

Operating temperature max.	50 °C
----------------------------	-------