



LED-INDICATOR RED/GREEN

LED 5mm - 24V DC - 15mA - IP67

(red/green)
24 V DC
Protection IP67
with touch protection

Link do produto

Ilustração

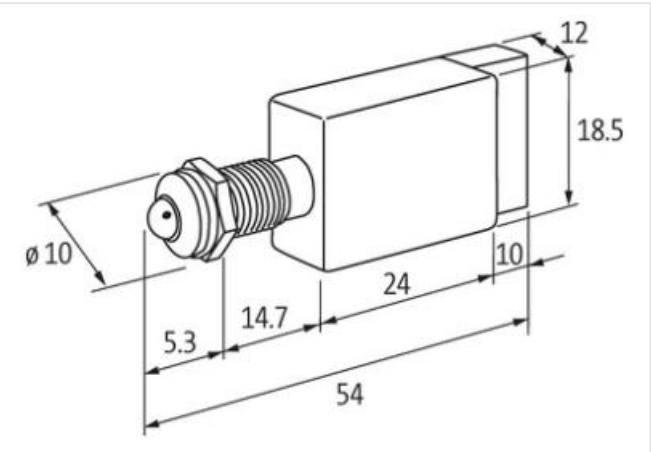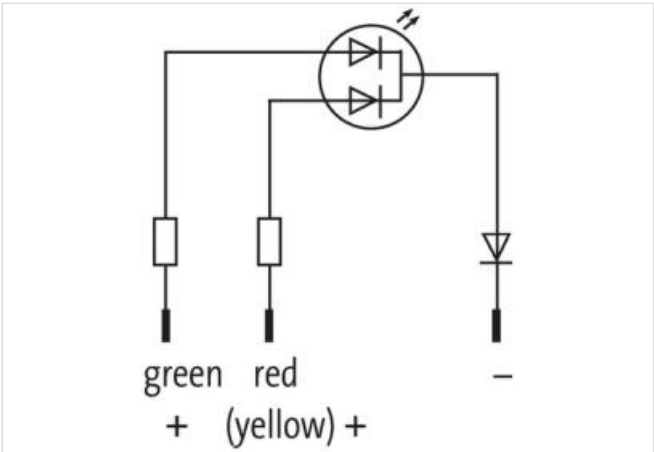

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27261590
ECLASS-6.1	27261501
ECLASS-7.0	27261501
ECLASS-8.0	27261501
ECLASS-9.0	27261501
ECLASS-10.1	27261501
ECLASS-11.1	27261501
ECLASS-12.0	27261501
ETIM-5.0	EC000272
Classificação fiscal	85318070

GTIN	4048879040556
------	---------------

Quantidade por embalagem	10
--------------------------	----

Electrical data | Supply

Operating voltage DC	24 V
----------------------	------

Operating voltage DC min.	20,4 V
---------------------------	--------

Operating voltage DC max.	26,4 V
---------------------------	--------

Current consumption min.	13 mA
--------------------------	-------

Current consumption max.	17 mA
--------------------------	-------

Installation | Connection

Connection information	Faston 2.8x0.8 mm
------------------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Mechanical data

Diameter LED	5 mm
--------------	------

Mechanical data | Material data

Color housing	gray
---------------	------

Material housing	PVC
------------------	-----

Mechanical data | Mounting data

Diameter front panel drilling	8 mm
-------------------------------	------

Height	18,5 mm
--------	---------

Width	12 mm
-------	-------

Depth	54 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------