



MPS POWER SUPPLY 3-PHASE,

IN: 360-550VAC OUT: 22-28V/20ADC

INPUT: 3× 360...550 V AC
OUTPUT: 22...28 V DC
Current: 20 A
Protection IP20
Wide voltage input
Units decoupling through diode block at parallel usage.
additional mounting feet for screw mounting part no. 89500

Link do produto

Ilustração

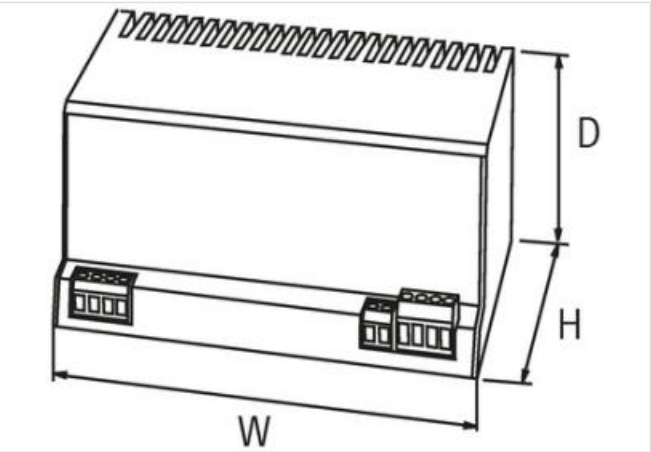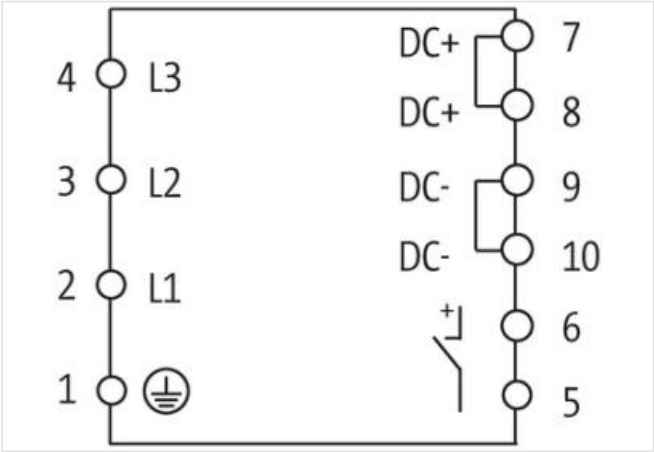

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002

ECLASS-9.0	27040701
ETIM-5.0	EC002540
Classificação fiscal	85044083
GTIN	4048879080606
Quantidade por embalagem	1

Electrical data

Parallel connection	yes
Series connection	yes
Security level	SELV

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC min.	360 V
Input voltage AC max.	550 V
Input current AC (3-phase)	0,84 A
External back-up fuse per phase max.	10 A
Phase number input	3
Efficiency	90 %

Electrical data | Output

Output voltage DC	24 V
Output voltage DC min.	22 V
Output voltage DC max.	28 V
Output voltage adjustable	yes
Output current	20 A
Output current (UL)	24 A
Mains failure bridging min.	3 ms @ 400 V AC
Phase monitoring	Switching off during 2-phase operation
Ripple effective max.	20 mV
Spikes (s-s) max.	100 mV

Device protection | Electrical

Overload protection output	yes
Short-circuit protection output	yes

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	132 mm
Width	243 mm
Depth	123 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C
Relative humidity min. (operation)	30 %
Relative humidity max. (operation)	90 % no condensation

Connection type 3

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green

No. of poles	2
PIN 1	Signal
PIN 2	Signal +
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	PE
PIN 2	L 1
PIN 3	L 2
PIN 4	L 3
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	+
PIN 2	+
PIN 3	-
PIN 4	-