



Emparro ACCUcontrol UPS-Module

IN: 24VDC OUT: 24VDC/20A

INPUT: 24 V DC (SELV/PELV)  
OUTPUT: max. 20 A

Link do produto

Ilustração

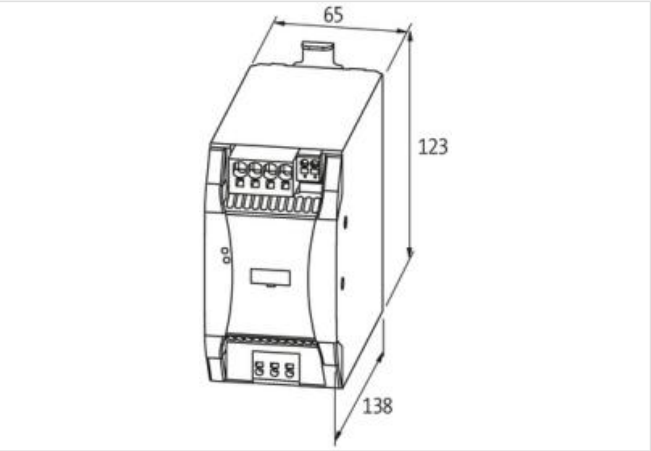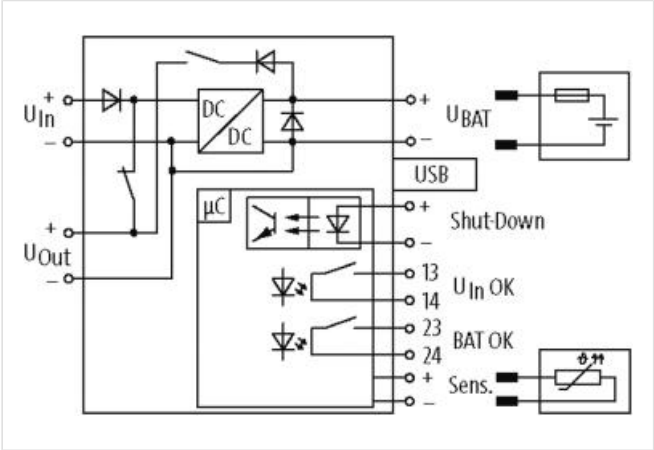

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27049002 |
| ECLASS-6.1       | 27049002 |
| ECLASS-7.0       | 27049002 |
| ECLASS-8.0       | 27049002 |
| ECLASS-9.0       | 27040705 |
| ECLASS-10.1      | 27040705 |
| ECLASS-11.1      | 27040705 |
| ECLASS-12.0      | 27040705 |

|                          |               |
|--------------------------|---------------|
| ETIM-5.0                 | EC002540      |
| Classificação fiscal     | 85371091      |
| GTIN                     | 4048879694339 |
| Quantidade por embalagem | 1             |

**Electrical data**

|                                   |                     |
|-----------------------------------|---------------------|
| Battery type                      | lead battery closed |
| Load capacity alarm contacts min. | 5 V, 1 mA           |
| Load capacity alarm contacts max. | 30 V, 100 mA        |
| Electric charge quantity max.     | 40 Ah               |

**Electrical data | Input**

|                                      |                            |
|--------------------------------------|----------------------------|
| Input voltage DC shutdown input      | 24 V                       |
| Input voltage DC shutdown input min. | 6 V                        |
| Input voltage DC shutdown input max. | 45 V                       |
| Input voltage DC min.                | 21,6 V                     |
| Input voltage DC max.                | 30 V                       |
| Input current DC max.                | 23 A                       |
| Charging current max.                | 2,5 A                      |
| Switching input potential free       | yes                        |
| Sensor type                          | KTY 81-210 (Art.No. 89600) |

**Electrical data | Output**

|                           |        |
|---------------------------|--------|
| Output voltage DC min.    | 19,2 V |
| Output voltage DC max.    | 27,7 V |
| Output voltage adjustable | yes    |
| Output current max.       | 20 A   |

**Mechanical data | Mounting data**

|                            |                                          |
|----------------------------|------------------------------------------|
| Mounting method            | geschnappt                               |
| Suitable for mounting type | Tragschiene TH35-7.5/TH35-15, (EN 60715) |
| Height                     | 123 mm                                   |
| Width                      | 65 mm                                    |
| Depth                      | 143 mm                                   |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -25 °C |
| Operating temperature max. | 45 °C  |

**Connection type 3**

|                          |                           |
|--------------------------|---------------------------|
| Connection type 1        | X1                        |
| Connection type 2        | X2                        |
| Connection type 3        | X3                        |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | green                     |
| No. of poles             | 6                         |
| PIN 1                    | U In -                    |
| PIN 2                    | U In +                    |
| PIN 3                    | U Out -                   |
| PIN 4                    | U Out +                   |
| PIN 5                    | U Bat -                   |
| PIN 6                    | U Bat +                   |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |

|                          |          |
|--------------------------|----------|
| Color contact carrier    | green    |
| No. of poles             | 8        |
| PIN 1                    | Sens +   |
| PIN 2                    | Sens -   |
| PIN 3                    | U In 13  |
| PIN 4                    | OK 14    |
| PIN 5                    | Bat 23   |
| PIN 6                    | OK 24    |
| PIN 7                    | SH +     |
| PIN 8                    | SH -     |
| Family construction form | USB Mini |
| Gender                   | female   |
| Color contact carrier    | red      |
| No. of poles             | 5        |
| PIN 1                    | 5 V      |
| PIN 2                    | Data -   |
| PIN 3                    | Data +   |
| PIN 4                    | ID       |
| PIN 5                    | 0 V      |