


GSS DC/DC-CONVERTOR SWITCH MODE

IN: 15-40VDC OUT: 5V/4ADC

INPUT: 24 V DC
OUTPUT switched mode: 5 V DC
Output rating: 20 W
Current: 4 A
Condensation not permitted

Link do produto

Ilustração

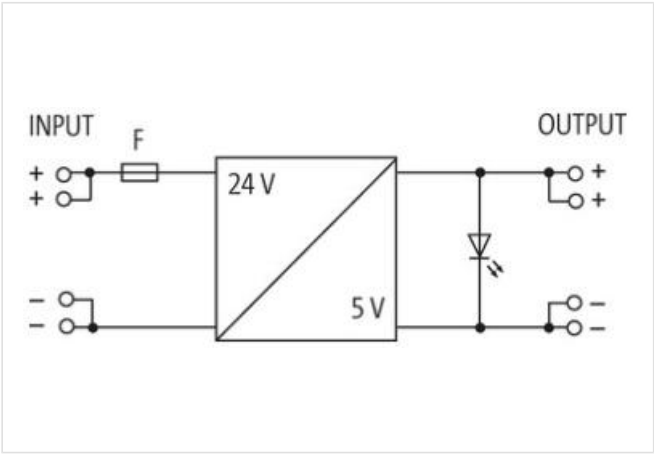

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27210901
ECLASS-6.1	27210901
ECLASS-7.0	27210901
ECLASS-8.0	27210901
ECLASS-9.0	27210901

ECLASS-10.1	27210901
ECLASS-11.1	27210901
ECLASS-12.0	27210901
ETIM-5.0	EC002540
Classificação fiscal	85044095
GTIN	4048879079563
Quantidade por embalagem	1

Electrical data

Security level	SELV
----------------	------

Electrical data | Input

Fuse protection primary side internal	2 A
Characteristic back-up fuse	Inertia
Input voltage DC	24 V
Input voltage DC min.	15 V
Input voltage DC max.	40 V
Current input DC	1,04 A
Input current DC max.	1,7 A

Electrical data | Output

Output voltage DC	5 V
Output voltage DC min.	4,75 V
Output voltage DC max.	5,25 V
Output voltage adjustable	no
Output current max.	4 A
Ripple max.	0,2 %

Device protection | Electrical

Short-circuit protected	yes
-------------------------	-----

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 1

Connection type 1	Output
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	+
PIN 2	+
PIN 3	-
PIN 4	-