

MET 1-PHASE SAFETY TRANSFORMER

P: 500VA IN: 230VAC $\pm$ 5% OUT: 24VAC



Single-phase safety transformer

500 VA

Isolation class T 60/B

Link do produto

Ilustração

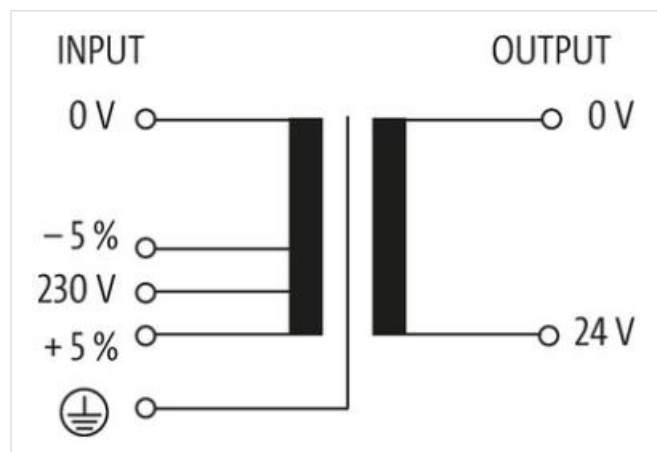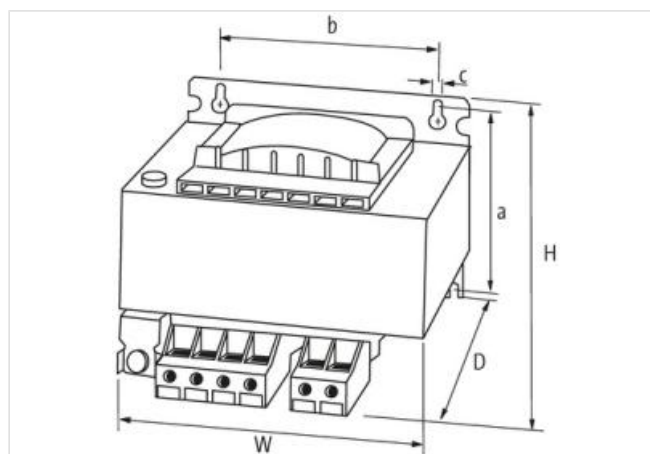

Produto pode diferir da imagem



Dados comerciais

ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado.
A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 22/05/2024

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
Classificação fiscal	85043180
GTIN	4048879079037
Quantidade por embalagem	1
Electrical data	
Security level	SELV
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	230 V
Input voltage AC min.	218,5 V
Input voltage AC max.	241,5 V
Current input AC	2,3 A
Max. inrush current	35,45 A
Short-circuit current	74,76 A
Electrical data Output	
Output voltage AC	24 V
Output voltage adjustable	no
Power rating AC max.	500 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	91 mm
Mounting dimension b	122 mm
Mounting dimension c	7 mm
Height	112,6 mm
Width	150 mm
Depth	146 mm
Diameter bore	7 mm
Length bore	11 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-2-4, EN 61558-2-6, EN 62041 category 0