



MET 1-PHASE SAFETY TRANSFORMER

P: 630VA IN: 230VAC+/- 5% OUT: 24VAC

Single-phase safety transformer  
630 VA  
Isolation class T 60/B

[Link do produto](#)

Ilustração

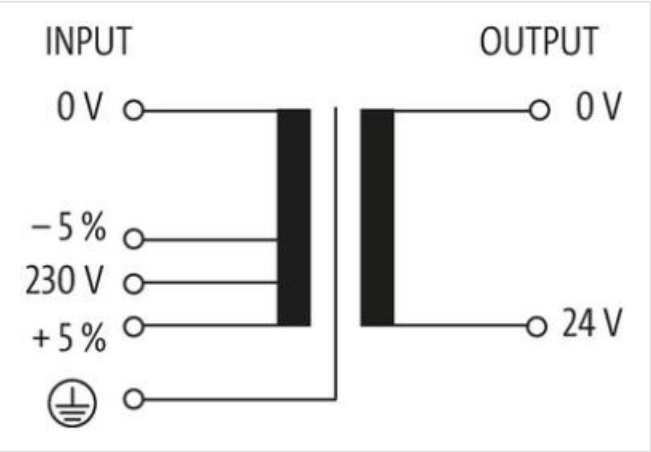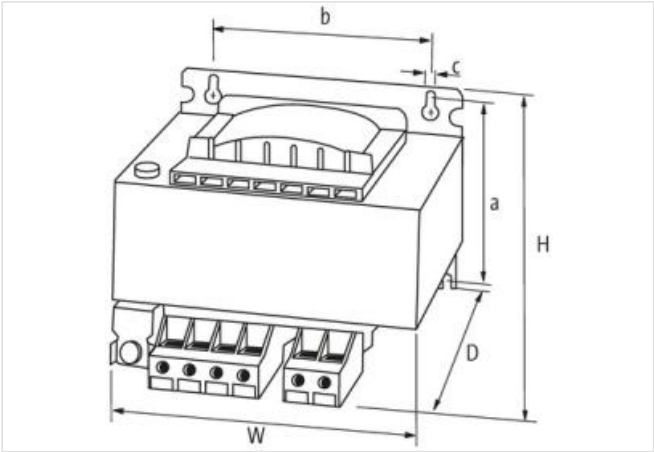

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27031302 |
| ECLASS-6.1       | 27031302 |
| ECLASS-7.0       | 27031302 |
| ECLASS-8.0       | 27031302 |
| ECLASS-9.0       | 27031302 |
| ECLASS-10.1      | 27031302 |

|                                                 |                                                 |
|-------------------------------------------------|-------------------------------------------------|
| ECLASS-11.1                                     | 27031302                                        |
| ECLASS-12.0                                     | 27031302                                        |
| ETIM-5.0                                        | EC002486                                        |
| Classificação fiscal                            | 85043180                                        |
| GTIN                                            | 4048879078986                                   |
| Quantidade por embalagem                        | 1                                               |
| <b>Electrical data</b>                          |                                                 |
| Security level                                  | SELV                                            |
| <b>Electrical data   Supply</b>                 |                                                 |
| Power frequency                                 | 50 ... 60 Hz                                    |
| <b>Electrical data   Input</b>                  |                                                 |
| Input voltage AC                                | 230 V                                           |
| Input voltage AC min.                           | 218,5 V                                         |
| Input voltage AC max.                           | 241,5 V                                         |
| Current input AC                                | 2,98 A                                          |
| Max. inrush current                             | 75,6 A                                          |
| Short-circuit current                           | 82,3 A                                          |
| <b>Electrical data   Output</b>                 |                                                 |
| Output voltage AC                               | 24 V                                            |
| Output voltage adjustable                       | no                                              |
| Power rating AC max.                            | 630 VA                                          |
| <b>Device protection   Electrical</b>           |                                                 |
| Insulation test voltage input - output          | 4 kV                                            |
| <b>Mechanical data   Mounting data</b>          |                                                 |
| Suitable for mounting type                      | Schlüssellochabhängung                          |
| Mounting dimension a                            | 107,5 mm                                        |
| Mounting dimension b                            | 122 mm                                          |
| Mounting dimension c                            | 7 mm                                            |
| Height                                          | 129 mm                                          |
| Width                                           | 150 mm                                          |
| Depth                                           | 148 mm                                          |
| Diameter bore                                   | 7 mm                                            |
| Length bore                                     | 11 mm                                           |
| <b>Environmental characteristics   Climatic</b> |                                                 |
| Operating temperature min.                      | -20 °C                                          |
| Operating temperature max.                      | 60 °C                                           |
| Storage temperature min.                        | -40 °C                                          |
| Storage temperature max.                        | 80 °C                                           |
| <b>Conformity</b>                               |                                                 |
| Product standard                                | EN 61558-2-4, EN 61558-2-6, EN 62041 category 0 |