

MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

3× 575 V AC



RC

with ferrule ends

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link do produto

Ilustração

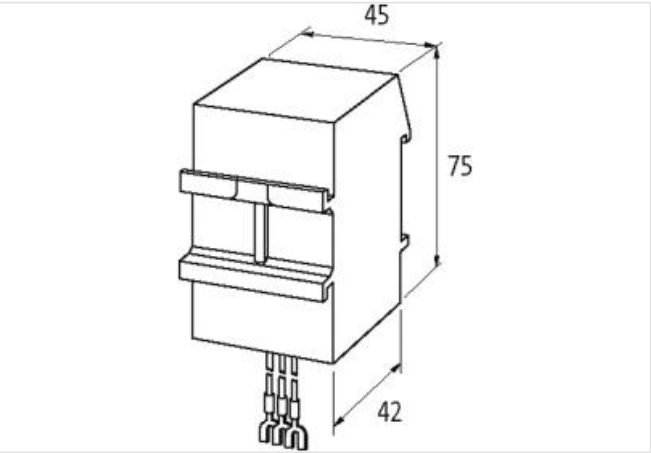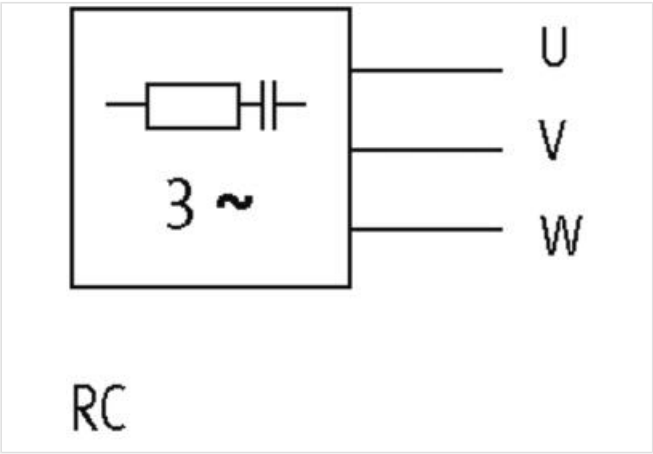

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
Classificação fiscal	85363010
GTIN	4048879015820
Quantidade por embalagem	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	575 V
Installation	
Connection cross-section stranded/fine-stranded min.	0,5 mm ²
Installation Connection	
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4
Length single strands	250 mm
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	75 mm
Width	45 mm
Depth	42 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C