

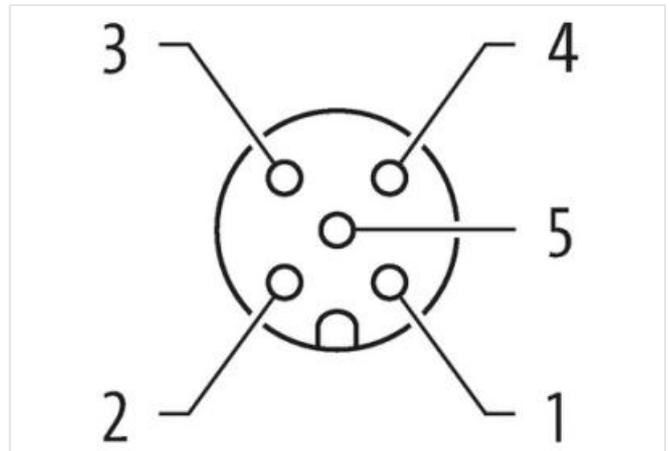
M12-DISTRIBUTOR BOX 8-WAY, 5-POLE WITHOUT LED

MVC8-UQQ10.0-XA 10m PUR-CNOMO-cable 16x0,34/3x1

8-way, 5-pole
 PUR/PVC (CNOMO)
 10.0 m
 without LED
 Further cable lengths on request.

Link do produto**Ilustração**

Produto pode diferir da imagem

**Dados comerciais**

ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108
ETIM-5.0	EC002585
Classificação fiscal	85444290
GTIN	4048879000215
Quantidade por embalagem	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	10 A

Industrial communication

Number of signals per port	2
----------------------------	---

Installation | Connection

Mounting set	M12 x 1
--------------	---------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Additional condition protection degree inserted, screwed

Mechanical data | Mounting data

Mounting method	Schraubgewinde
Height	127 mm
Width	54 mm
Depth	29 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Connection type 2

Family construction form	free cable end
No. of poles	19
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	+
PIN 3	-
PIN 5	PE