
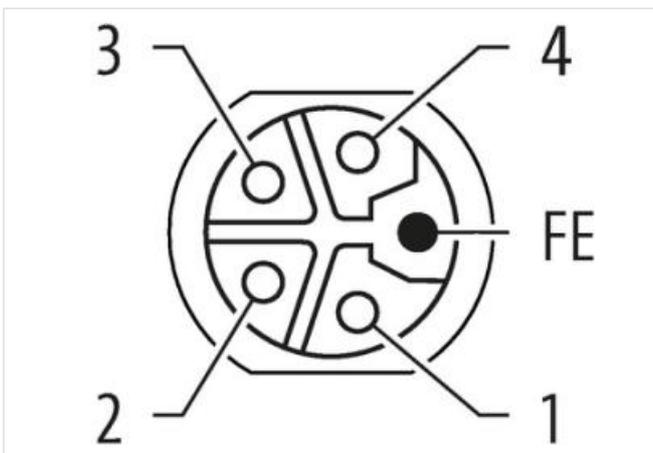


## Power Distributor 4x L-cod.

Passive power distributor in zinc die-cast housing  
B24 with locking on both sides  
Industrial connector 24-pin + PE to 4x M12 L 5P female

### Link do produto

#### Ilustração

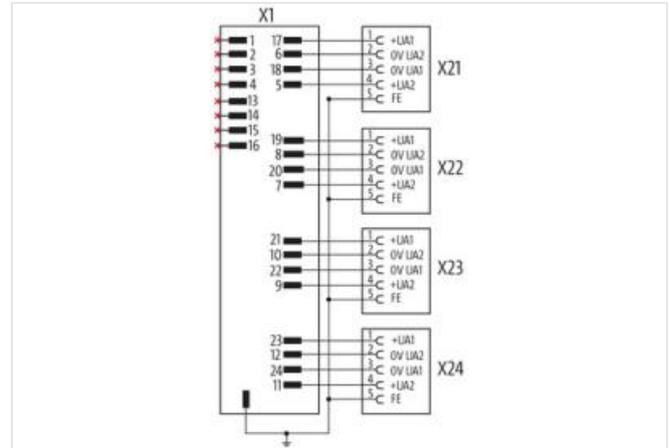

Produto pode diferir da imagem

#### Electrical data | Supply

Operating voltage AC	48 V
Operating voltage DC	48 V
Current operating per contact max.	16 A

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked

#### Mechanical data | Material data

Coating housing	powder-coated
Material housing	Aluminum die casting

#### Mechanical data | Mounting data

Height	94 mm
Width	61 mm

Depth	149 mm
Looking techniques	2-hand fixing (2 clamps)

**Environmental characteristics | Climatic**

Operating temperature min.	-25 °C
Operating temperature max.	70 °C
Storage temperature min.	-25 °C
Storage temperature max.	85 °C

**Dados comerciais**

Classificação fiscal	85366990
GTIN	4048879867504
Quantidade por embalagem	1