
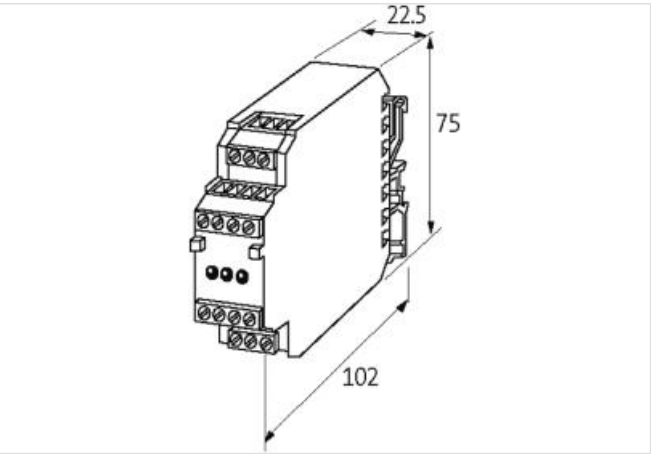


DEMAGNETIZER 1,5 A


INPUT: 24 V DC
OUTPUT: 24 V DC
max. 1.5 A (short-circuit protected)
Screw terminals

Link do produto

Ilustração

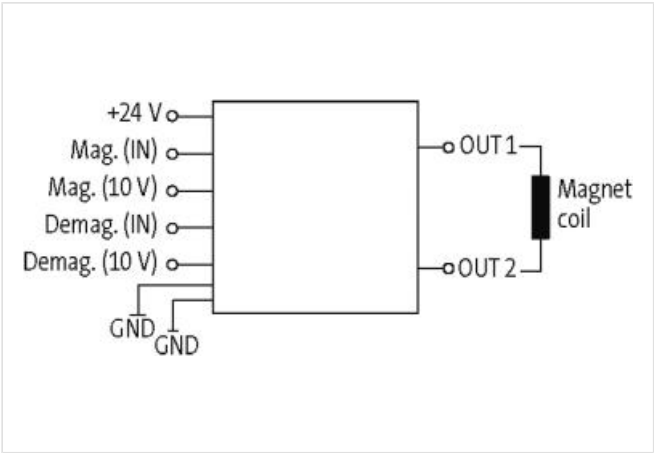

Produto pode diferir da imagem

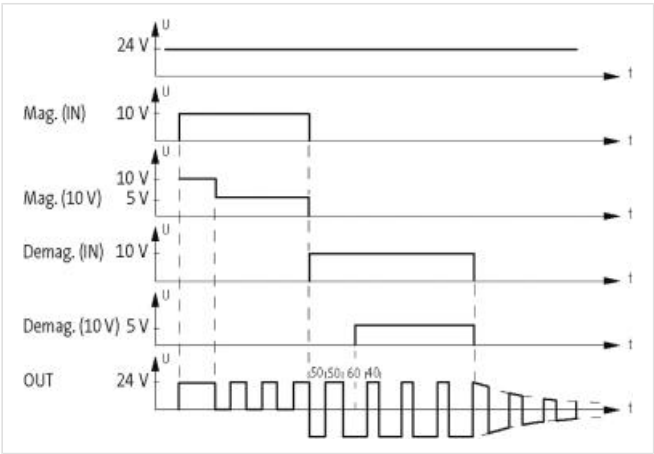

Dados comerciais	
ECLASS-6.0	27210990
ECLASS-6.1	27379090
ECLASS-7.0	27379090
ECLASS-8.0	27379090
ECLASS-9.0	27379090
ECLASS-10.1	27379090
ECLASS-11.1	27379090
ECLASS-12.0	27379090

ETIM-5.0	EC001504
Classificação fiscal	85437090
GTIN	4048879025058
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	18 V
Operating voltage DC max.	30 V
Operating current max.	40 mA
Electrical data Input	
Resistance input min.	10 kΩ
Demagnetization analog input	0 ... 10 V (44 ... 55 %) PWM
Demagnetization digital input	safe OFF: max. 1 V, safe ON: min. 5 V (LED yellow)
Magnetization analog input	0.8 ... 8.8 V (0 ... 100 %) PWM
Magnetization digital input	safe OFF: max. 1 V, safe ON: min. 5 V (LED yellow)
Electrical data Output	
Output voltage DC	24 V
Output voltage adjustable	no
Output current max.	1,5 A
PWM frequency	800 Hz
Diagnostics	
Status indication LED	green
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Invers-polarity protection	yes
Short-circuit protected	yes
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	22,5 mm
Depth	102 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	50 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Connection type 4	
Connection type 1	X2
Connection type 2	X2
Connection type 3	X3
Connection type 4	X4
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	3
PIN 1	n.c.
PIN 2	n.c.
PIN 3	n.c.
Connection	Spring clamp terminals FK
Family construction form	terminal

Gender	female
No. of poles	3
PIN 1	10 VM
PIN 2	10 VE
PIN 3	0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	Out 2
PIN 2	Out 2
PIN 3	Out 1
PIN 4	Out 1
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
No. of poles	4
PIN 1	INM
PIN 2	INE
PIN 3	0 V
PIN 4	24 V DC