



MIRO 6,2 Valvecontrol 24VDC/1ms

In:24VDC OUT:24VDC/1,5A

Switching accelerator: 1 ms/24 V DC
Screw terminals

[Link do produto](#)

Ilustração

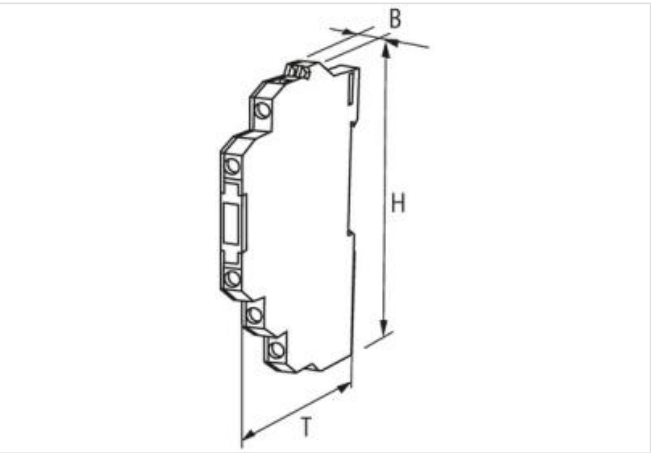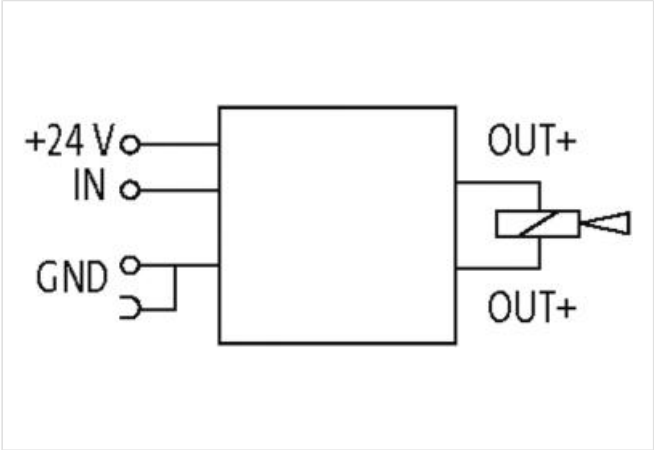

Produto pode diferir da imagem



Electrical data Input	
Input voltage DC	24 V
Input voltage DC min.	18 V
Input voltage DC max.	30 V
Input current	13 mA
Electrical data Output	
Output current	1,5 A
Output current max.	0,38 A

Duration surge current max.	1 ms
Switching frequency max.	20 Hz
Surge current max.	1,5 A

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	91 mm
Width	6,2 mm
Depth	71 mm

Environmental characteristics | Climatic

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-25 °C
Storage temperature max.	50 °C

Connection type 4

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	GD

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	In

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	O 1

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	O 2

Dados comerciais

Classificação fiscal	85437090
GTIN	4048879571876
Quantidade por embalagem	10