
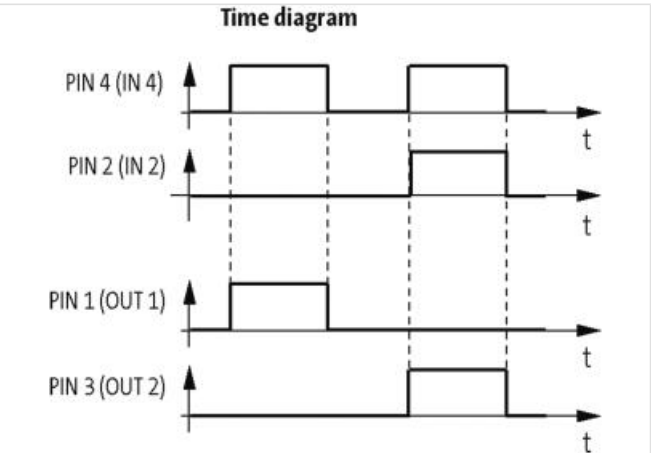


DC MOTOR CONTROL 24V/1A 2X M12

DC Motor control  
24 V DC  
Current: 1 A

Link do produto

Ilustração

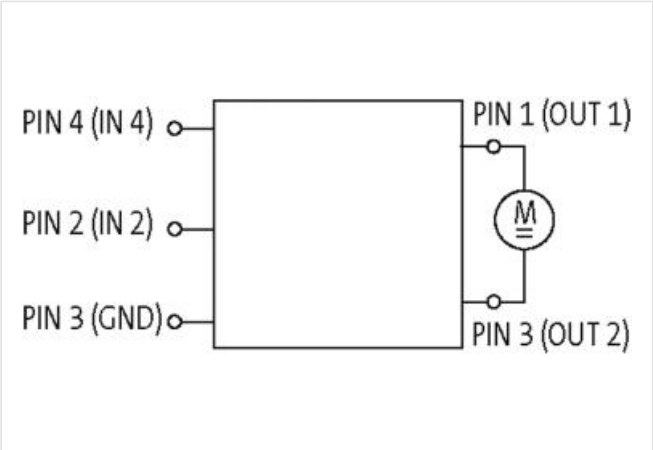

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27242609 |
| ECLASS-6.1       | 27242609 |
| ECLASS-7.0       | 27242609 |
| ECLASS-8.0       | 27242609 |
| ECLASS-9.0       | 27242609 |
| ECLASS-10.1      | 27242609 |
| ECLASS-11.1      | 27242609 |
| ECLASS-12.0      | 27242609 |

|                                                 |                                           |
|-------------------------------------------------|-------------------------------------------|
| ETIM-5.0                                        | EC002615                                  |
| Classificação fiscal                            | 85365080                                  |
| GTIN                                            | 4048879315111                             |
| Quantidade por embalagem                        | 1                                         |
| <b>Electrical data   Input</b>                  |                                           |
| Input voltage DC                                | 24 V                                      |
| Input voltage DC min.                           | 5 V                                       |
| Input voltage DC max.                           | 32 V                                      |
| Input current                                   | 1000 mA                                   |
| <b>Electrical data   Output</b>                 |                                           |
| Output voltage adjustable                       | no                                        |
| Output current max.                             | 1 A                                       |
| <b>Installation   Connection</b>                |                                           |
| Family construction form                        | M12                                       |
| <b>Device protection   Electrical</b>           |                                           |
| Degree of protection (EN IEC 60529)             | IP67                                      |
| Additional condition protection degree          | inserted, screwed                         |
| Protective circuit output                       | yes, yes, Suppressor diode, 1,5 kW / 36 V |
| Over voltage protection                         | yes                                       |
| <b>Mechanical data   Mounting data</b>          |                                           |
| Height                                          | 24,5 mm                                   |
| Width                                           | 24,5 mm                                   |
| Depth                                           | 60,5 mm                                   |
| <b>Environmental characteristics   Climatic</b> |                                           |
| Operating temperature min.                      | 0 °C                                      |
| Operating temperature max.                      | 60 °C                                     |
| Storage temperature min.                        | -40 °C                                    |
| Storage temperature max.                        | 80 °C                                     |