



MDT THREE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:2000VA IN:3x400VAC OUT:3x400VAC

3-phase isolation transformer
2000 VA
Isolation class T 40/B
Other voltages on request.

Link do produto

Ilustração

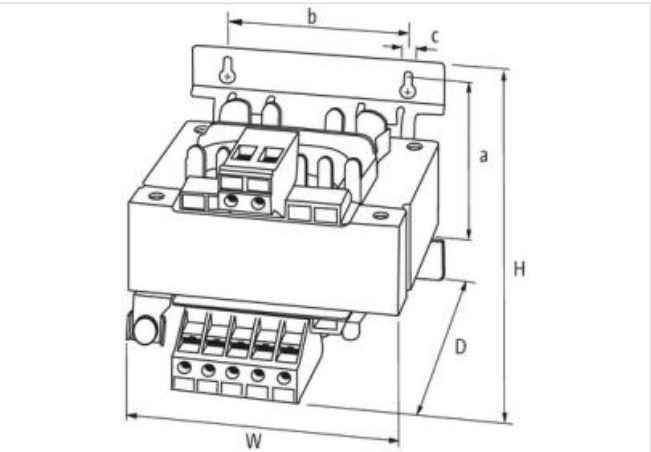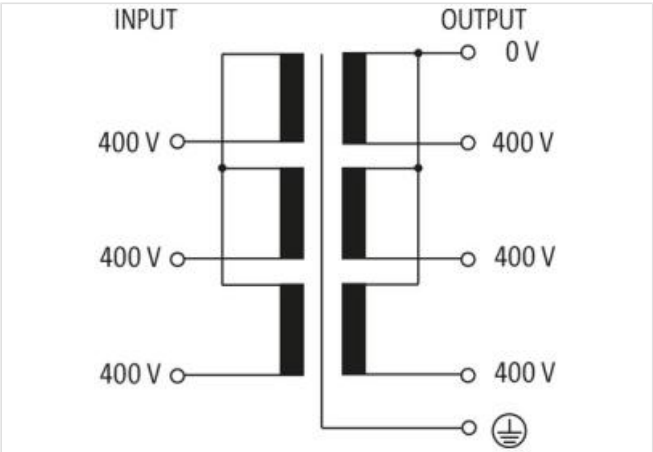

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27031301
ECLASS-6.1	27031301
ECLASS-7.0	27031301
ECLASS-8.0	27031301
ECLASS-9.0	27031301
ECLASS-10.1	27031301

ECLASS-11.1	27031301
ECLASS-12.0	27031301
ETIM-5.0	EC002485
Classificação fiscal	85043200
GTIN	4048879073905
Quantidade por embalagem	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Input current AC (3-phase)	3,1 A
Max. inrush current	81 A
Short-circuit current	103 A
Phase number input	3

Electrical data | Output

Output voltage	3× 400 V AC
Output voltage AC	400 V
Output voltage adjustable	no
Power rating AC max.	2000 VA

Device protection | Electrical

Insulation test voltage input - output	5,8 kV
--	--------

Mechanical data | Mounting data

Mounting method	screwed
Mounting dimension a	115 mm
Mounting dimension b	190 mm
Mounting dimension c	11 mm
Height	141 mm
Width	240 mm
Depth	265 mm
Diameter bore	11 mm
Length bore	15 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-20 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0
------------------	---