



MET SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:1000VA IN:400VAC±5% OUT:110VAC

Single-phase - Control and Isolation Transformers
1000 VA
Isolation class T 40/B

Link do produto

Ilustração

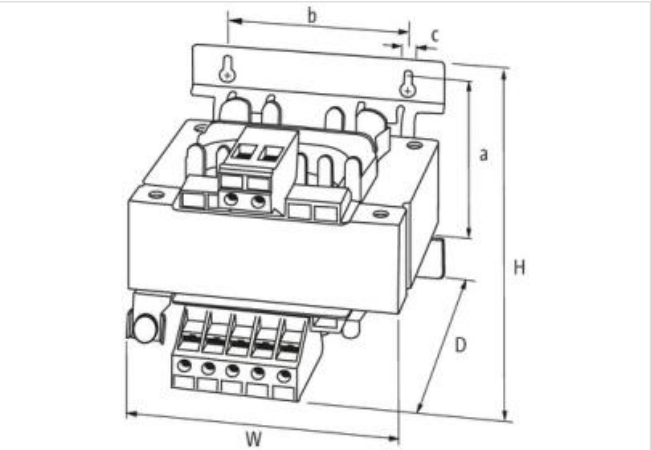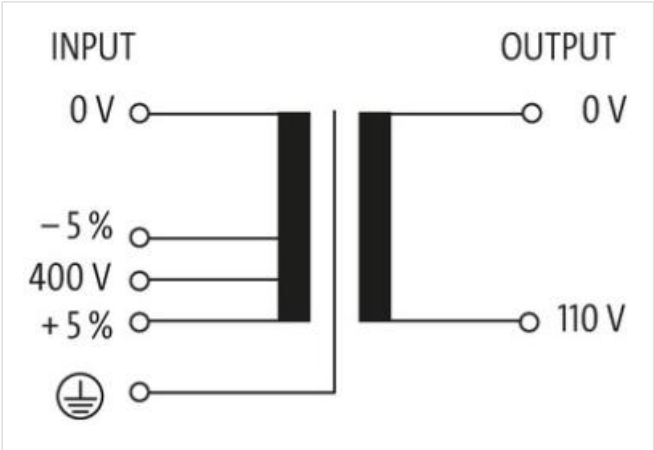

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27031202
ECLASS-7.0	27031202
ECLASS-8.0	27031202
ECLASS-9.0	27031202
ETIM-5.0	EC002485
Classificação fiscal	85043180
GTIN	4048879073875
Quantidade por embalagem	1

Electrical data Supply	
Power frequency	50 ... 60 Hz

Electrical data Input	
-------------------------	--

Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Current input AC	2,67 A
Max. inrush current	50 A
Short-circuit current	92 A

Electrical data | Output

Output voltage AC 1	110 V
Output voltage adjustable	no
Power rating AC max.	1000 VA

Device protection | Electrical

Insulation test voltage input - output	5,8 kV
--	--------

Mechanical data | Mounting data

Mounting method	screwed
Mounting dimension a	111,5 mm
Mounting dimension b	135 mm
Mounting dimension c	7 mm
Height	140 mm
Width	174 mm
Depth	163 mm
Diameter bore	7 mm
Length bore	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-20 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0
------------------	---