


MST SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:250VA IN:230/400±15VAC OUT:115VAC

Single-phase - Control and Isolation Transformers
250 VA
Isolation class T 40/B
Other voltages on request.

Link do produto

Ilustração

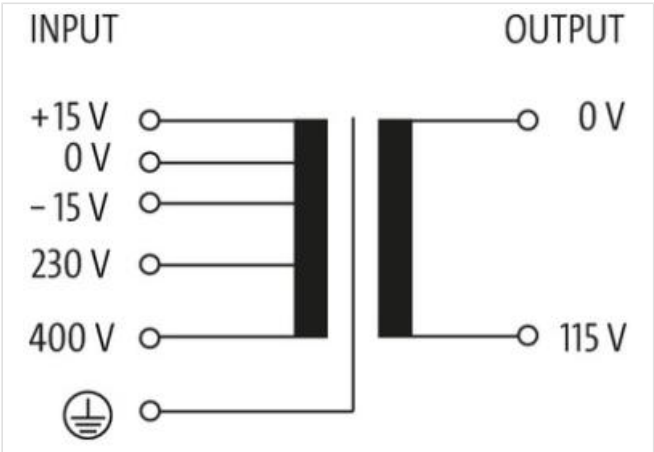

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27031202
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
Classificação fiscal	85043180
GTIN	4048879328562
Quantidade por embalagem	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage 1 AC	230 V
Input voltage 1 AC min.	195,5 V
Input voltage 1 AC max.	264,5 V
Input voltage 2 AC	400 V
Input voltage 2 AC min.	340 V
Input voltage 2 AC max.	460 V
Input current at input voltage 1 AC	1,25 A
Input current at input voltage 2 AC	0,72 A
Inrush current at input voltage 1	12 A
Inrush current at input voltage 2	7 A
Short-circuit current at input voltage 1	19 A
Short-circuit current at input voltage 2	11 A

Electrical data | Output

Output voltage AC	115 V
Output voltage adjustable	no
Power rating AC max.	250 VA

Device protection | Electrical

Insulation test voltage input - output	5,8 kV
--	--------

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	84 mm
Mounting dimension b	84 mm
Mounting dimension c	5,8 mm
Height	104,3 mm
Width	96 mm
Depth	105 mm
Diameter bore	5,8 mm
Length bore	10 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-2-6, EN 62041 category 0
------------------	-----------------------------------

Connection type 3

Connection type 1	Input
Connection type 2	Output
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	5

PIN 1	+ 15 V
PIN 3	- 15 V
PIN 4	230 V
PIN 5	400 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	2
PIN 2	115 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	metallic
No. of poles	1
PIN 1	PE