



MTS SINGLE-PHASE SAFETY TRANSFORMER

P:30VA IN:230VAC OUT:24VAC max. 26,3VAC

Single-phase - Control and Isolation Transformers
30 VA
Isolation class T 40/B
Other voltages on request.

Link do produto

Ilustração

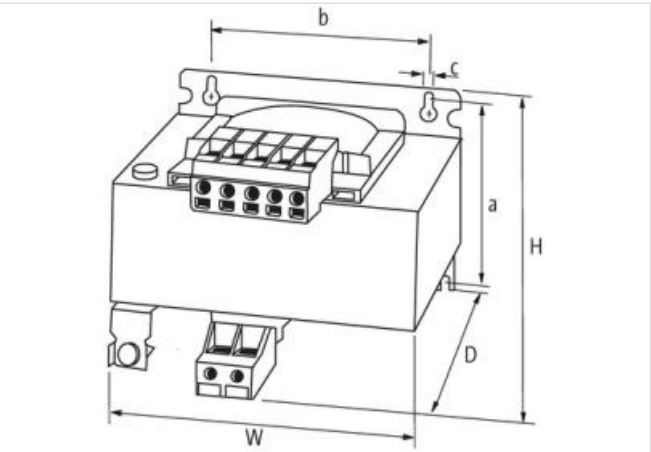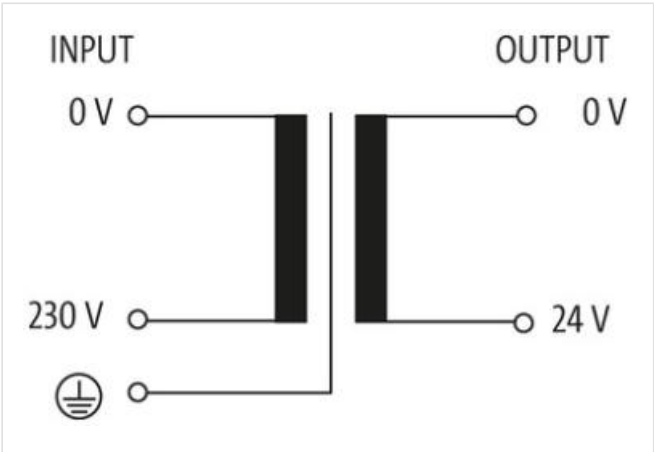

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27031202
ECLASS-7.0	27031202
ECLASS-8.0	27031202
ECLASS-9.0	27031202
ETIM-5.0	EC002486
Classificação fiscal	85043180
GTIN	4048879328807
Quantidade por embalagem	1
Electrical data Supply	
Power frequency	50 ... 60 Hz

Electrical data Input	
Input voltage 1 AC	230 V
Input voltage AC	230 V
Current input AC	0,15 A
Max. inrush current	0,8 A
Short-circuit current	3,1 A
Electrical data Output	
Output voltage AC	24 V
Output voltage adjustable	no
Power rating AC max.	30 VA
Device protection Electrical	
Insulation test voltage input - output	3,8 kV
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, Long-hole mounting, (EN 60715)
Mounting dimension a	56 mm
Mounting dimension b	56 mm
Mounting dimension c	4,8 mm
Height	92 mm
Width	79 mm
Depth	93 mm
Diameter bore	4,8 mm
Length bore	10 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	35 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-2-6, EN 62041 category 0
Connection type 3	
Connection type 1	Input
Connection type 2	Output
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	2
PIN 2	230 V
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
No. of poles	2
PIN 2	24 V DC
Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	metallic
No. of poles	1
PIN 1	PE