



VALVE PLUG SUPPRESSOR FORM A - 18MM

Varistor and LED, 24VAC/DC/50VA/W

24 V AC/DC  
VDR + LED  
Remove plug gasket when fitting adapter. Other LED colors on request.

Link do produto

Ilustração

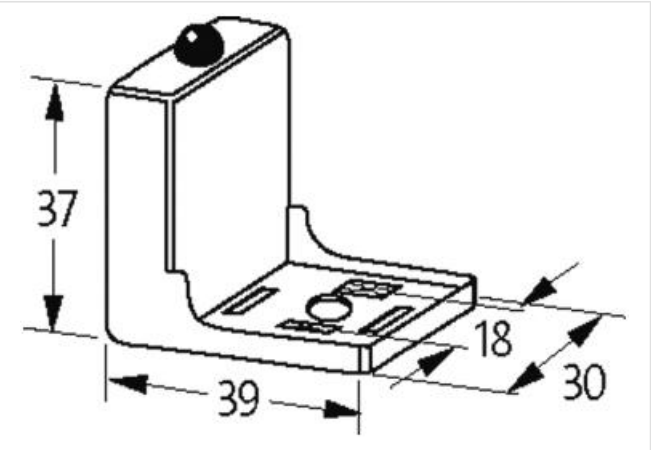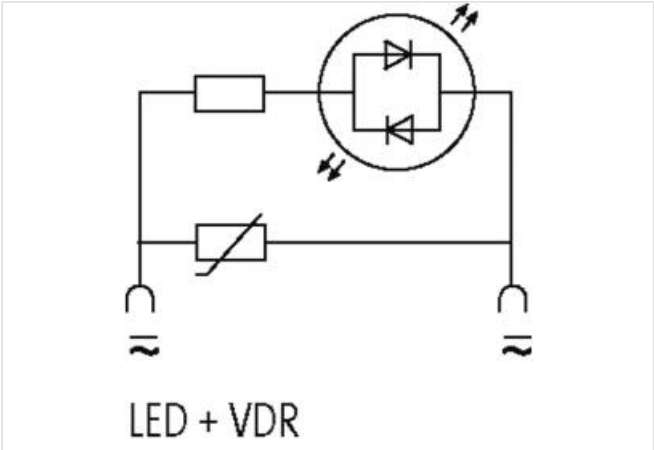

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27371013 |
| ECLASS-6.1       | 27371013 |
| ECLASS-7.0       | 27371013 |
| ECLASS-8.0       | 27371013 |
| ECLASS-9.0       | 27371013 |
| ECLASS-10.1      | 27371013 |

|                                                 |                 |
|-------------------------------------------------|-----------------|
| ECLASS-11.1                                     | 27371013        |
| ECLASS-12.0                                     | 27371013        |
| ETIM-5.0                                        | EC000197        |
| Classificação fiscal                            | 85363010        |
| GTIN                                            | 4048879012218   |
| Quantidade por embalagem                        | 1               |
| <b>Electrical data</b>                          |                 |
| Drop-out delay time min.                        | 15 ms           |
| Holding power max.                              | 50 W            |
| <b>Electrical data   Supply</b>                 |                 |
| Cut-off peak voltage max.                       | 45 V            |
| <b>Electrical data   Input</b>                  |                 |
| Input voltage AC min.                           | 12 V            |
| Input voltage AC max.                           | 25 V            |
| Input voltage DC min.                           | 12 V            |
| Input voltage DC max.                           | 25 V            |
| <b>Diagnostics</b>                              |                 |
| Status indication LED                           | yellow          |
| <b>Device protection   Media</b>                |                 |
| Flame resistance                                | flame retardant |
| <b>Mechanical data   Material data</b>          |                 |
| Coating contact                                 | silver-plated   |
| Color housing                                   | black           |
| Material housing                                | PA              |
| Material contact                                | Bronze          |
| <b>Mechanical data   Mounting data</b>          |                 |
| Height                                          | 37 mm           |
| Width                                           | 39 mm           |
| Depth                                           | 30 mm           |
| <b>Environmental characteristics   Climatic</b> |                 |
| Operating temperature min.                      | -20 °C          |
| Operating temperature max.                      | 60 °C           |
| Housing temperature max. (EN 61347-2-13)        | 130 °C          |