

CAP BIG WITH PLUG.SPRING-TERM 21-POLE

For use with 4-,6-,8-way d-box M12 5--pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole



Spring clamp plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link do produto](#)

Ilustração

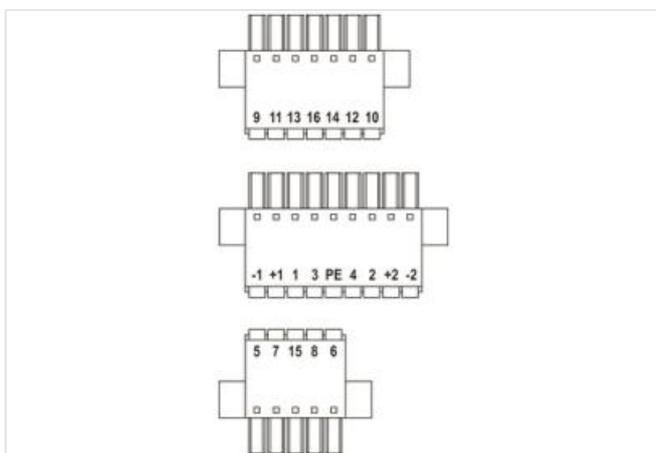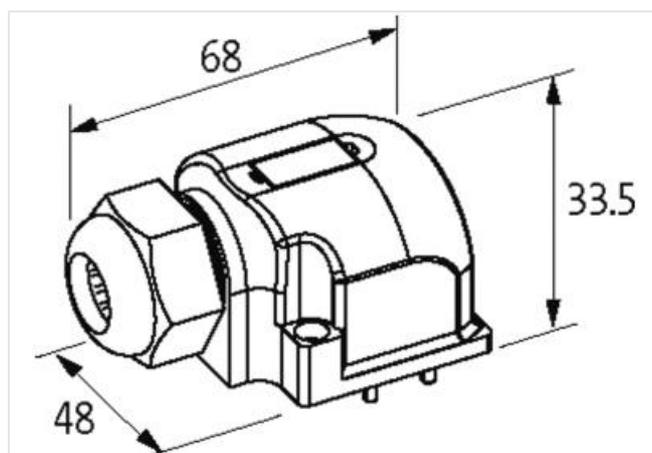

Produto pode diferir da imagem

Dados comerciais

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
Classificação fiscal	85369010

GTIN	4048879058018
------	---------------

Quantidade por embalagem	1
--------------------------	---

Electrical data | Supply

Total current max.	8 A
--------------------	-----

Installation

Connection cross section max.	1,5 mm ²
-------------------------------	---------------------

AWG number max.	16
-----------------	----

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Mechanical data | Mounting data

Height	33,5 mm
--------	---------

Width	48 mm
-------	-------

Depth	68 mm
-------	-------

Connection type 1

Family construction form	Cap
--------------------------	-----

No. of poles	21
--------------	----