


MIRO 6.2 OPTO-COUPLER MODULE

IN: 230 VAC/DC - OUT: 253 VAC/DC / 0,5 A

Multi voltage output
Transistor 0.5 A
24...230 V AC/DC
Spring clamp terminals

Link do produto

Ilustração

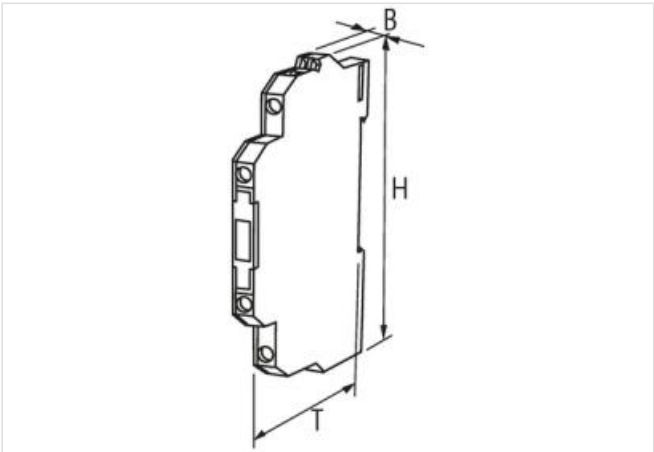

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371601
ECLASS-6.1	27371604
ECLASS-7.0	27371604
ECLASS-8.0	27371604
ECLASS-9.0	27371604
ECLASS-10.1	27371604
ECLASS-11.1	27371604
ECLASS-12.0	27371604
ETIM-5.0	EC001504
Classificação fiscal	85414900
GTIN	4048879021654
Quantidade por embalagem	1
Electrical data Input	
Input voltage AC min.	10 V
Input voltage AC max.	230 V
Input voltage OFF AC min.	0 V
Input voltage OFF AC max.	5 V
Input voltage OFF DC min.	0 V
Input voltage OFF DC max.	5 V
Input voltage DC min.	10 V
Input voltage DC max.	230 V

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado.
A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 20/04/2024

Current input AC max. 5 mA

Electrical data | Output

Switch off delay max.	15 ms
Switch on delay max.	5 ms
Quiescent current OFF max.	0,02 mA
Switching frequency max.	2,5 Hz
Voltage switching AC min.	10 V
Switching voltage AC max.	230 V
Voltage switching DC min.	10 V
Switching voltage DC max.	230 V
Switching current min.	1 mA
Switching current max.	0,5 A
Voltage drop AC max.	2,6 V
Voltage drop DC max.	2,6 V

Diagnostics

Status indication LED yellow

Device protection | Electrical

Rated insulation voltage 2750 V

Device protection | Media

Flame resistance flame retardant

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	78 mm
Width	6,2 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C

Connection type 4

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	13
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	14
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	A 1

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	A 2