

SIEMENS CONTACTOR SUPPRESSOR



Diode, 0...240VDC

24...240 V DC

Diode

[Link do produto](#)

Ilustração

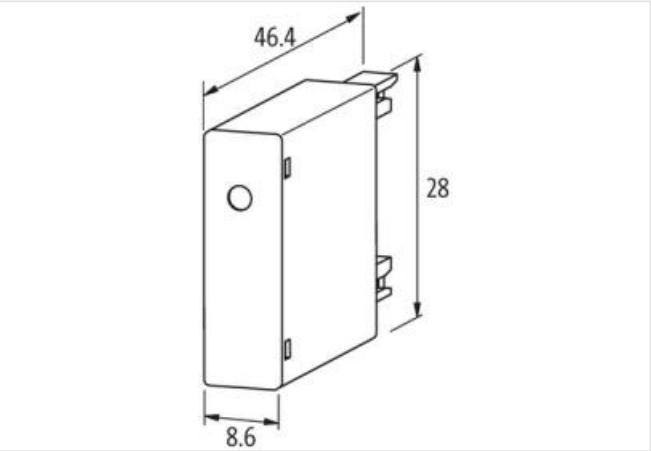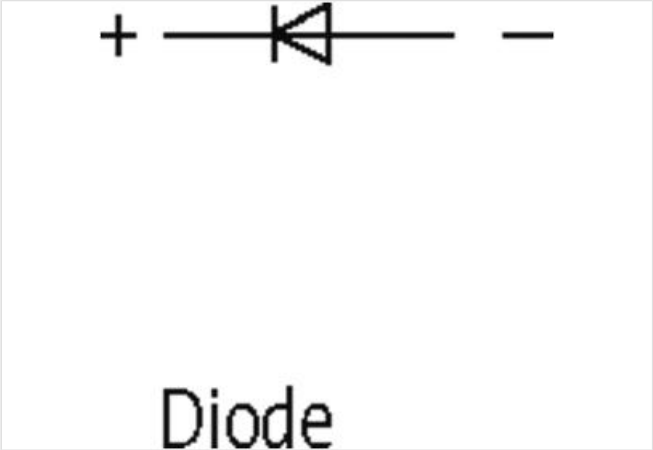

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado.
A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 13/05/2024

ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879010719
Quantidade por embalagem	1
Compatibility Compatible with	
Appropriate contactors	3 RT 20.15/16/17/18
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage DC min.	12 V
Input voltage DC max.	250 V
Installation Connection	
Connection information	Plug contact
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	46,4 mm
Width	28 mm
Depth	8,6 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C