

TELEMECANIQUE CONTACTOR SUPPRESSOR

RC, 400VAC/DC



400 V AC/DC

RC

For other configurations and voltages, please inquire.

Link do produto

Ilustração

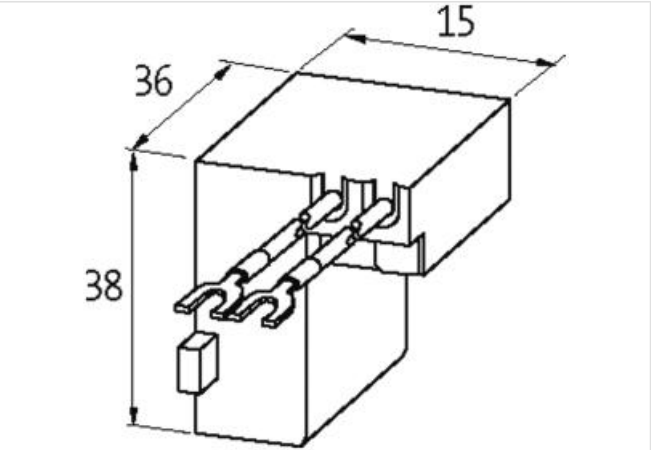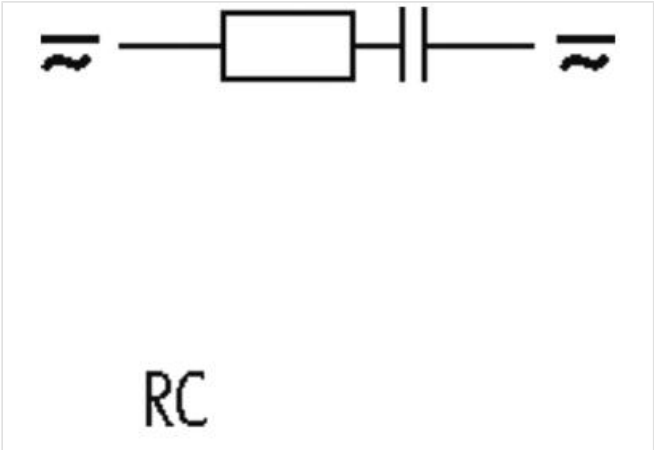

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
Classificação fiscal	85363010
GTIN	4048879010122
Quantidade por embalagem	1
Compatibility Compatible with	
Appropriate contactors	DT40, LC 1 D09...D38, LC 1 DT20, LC 2 D09...D38
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	253 V
Input voltage AC max.	450 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Mechanical data Mounting data	
Height	15 mm
Width	36 mm
Depth	38 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C