



MIRO SAFE+ E 24

24 VAC/DC - 4 N/O contact / 2 N/C contact

6 A  
Expansion modules

Link do produto

Ilustração

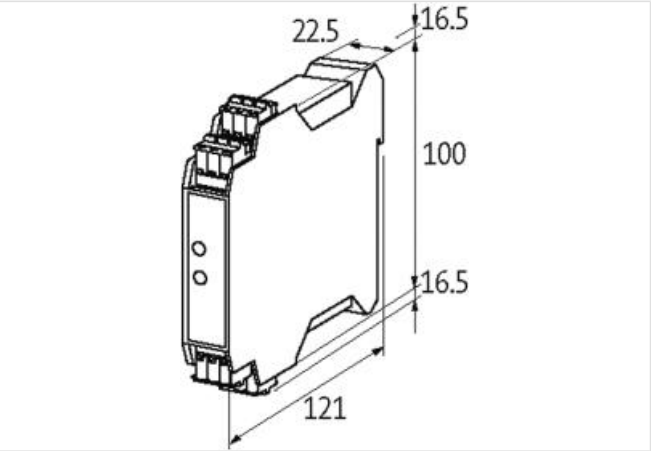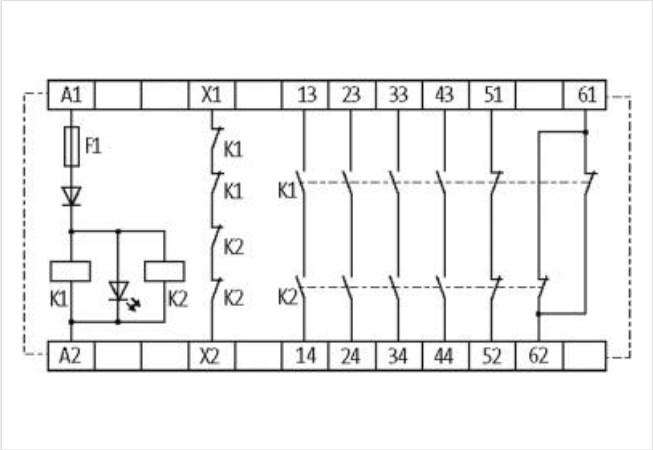

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27371819 |
| ECLASS-6.1       | 27371819 |
| ECLASS-7.0       | 27371819 |
| ECLASS-8.0       | 27371819 |
| ECLASS-9.0       | 27371819 |
| ECLASS-10.1      | 27371819 |
| ECLASS-11.1      | 27371819 |
| ECLASS-12.0      | 27371819 |

|                                                 |                                                                               |
|-------------------------------------------------|-------------------------------------------------------------------------------|
| ETIM-5.0                                        | EC001449                                                                      |
| Classificação fiscal                            | 85364900                                                                      |
| GTIN                                            | 4048879367622                                                                 |
| Quantidade por embalagem                        | 1                                                                             |
| <b>Safety codes</b>                             |                                                                               |
| Service life                                    | 20 a                                                                          |
| Category (EN ISO 13849-1)                       | 4                                                                             |
| Performance level (EN ISO 13849-1)              | e                                                                             |
| SIL (IEC 61508)                                 | 3                                                                             |
| <b>Electrical data   Supply</b>                 |                                                                               |
| Apparent power max.                             | 1,2 VA                                                                        |
| <b>Electrical data   Input</b>                  |                                                                               |
| Input voltage AC                                | 24 V                                                                          |
| Input voltage AC min.                           | 20,4 V                                                                        |
| Input voltage AC max.                           | 26,4 V                                                                        |
| Input voltage DC                                | 24 V                                                                          |
| Input voltage DC min.                           | 20,4 V                                                                        |
| Input voltage DC max.                           | 28,8 V                                                                        |
| <b>Electrical data   Output</b>                 |                                                                               |
| No. of auxiliary contacts                       | 2                                                                             |
| No. of alarm outputs                            | 0                                                                             |
| No. of safety contacts                          | 4                                                                             |
| Utilization category AC-15 (EN IEC 60947-5-1)   | 6 A @ 230 V                                                                   |
| Utilization category DC-13 (EN IEC 60947-5-1)   | 6 A @ 24 V                                                                    |
| Auxiliary contacts                              | 51-52, 61-62                                                                  |
| Switching voltage AC max.                       | 250 V                                                                         |
| Switching voltage DC max.                       | 250 V                                                                         |
| Safety contacts                                 | 13-14, 23-24, 33-34, 43-44                                                    |
| Switching current max.                          | 6 A                                                                           |
| Switching capacity safety contacts STOP0        | max. 250 V AC/6 A; min. 10 V AC/10 mA (resist./ind.), at suitable suppression |
| <b>Device protection</b>                        |                                                                               |
| Condition lifetime                              | load-dependent                                                                |
| <b>Device protection   Electrical</b>           |                                                                               |
| Electrical lifetime                             | 10000000 Cycles                                                               |
| <b>Device protection   Mechanical</b>           |                                                                               |
| Mechanical endurance                            | 10000000 Cycles                                                               |
| <b>Mechanical data   Material data</b>          |                                                                               |
| Material contact                                | Ag Sn O                                                                       |
| Material properties contact                     | positively driven, self-cleaning                                              |
| <b>Mechanical data   Mounting data</b>          |                                                                               |
| Mounting method                                 | geschnappt                                                                    |
| Suitable for mounting type                      | mounting rail, (EN 60715)                                                     |
| Height                                          | 100 mm                                                                        |
| Width                                           | 22,5 mm                                                                       |
| Depth                                           | 121 mm                                                                        |
| <b>Environmental characteristics   Climatic</b> |                                                                               |
| Operating temperature min.                      | -25 °C                                                                        |
| Operating temperature max.                      | 45 °C                                                                         |
| Storage temperature min.                        | -40 °C                                                                        |
| Storage temperature max.                        | 85 °C                                                                         |

**Connection type 4**

|                          |                           |
|--------------------------|---------------------------|
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 4                         |
| PIN 1                    | 14                        |
| PIN 2                    | 24                        |
| PIN 3                    | 34                        |
| PIN 4                    | 44                        |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 4                         |
| PIN 1                    | A 2                       |
| PIN 2                    | X 2                       |
| PIN 3                    | 52                        |
| PIN 4                    | 62                        |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 4                         |
| PIN 1                    | A 1                       |
| PIN 2                    | X 1                       |
| PIN 3                    | 51                        |
| PIN 4                    | 61                        |
| Connection               | Spring clamp terminals FK |
| Family construction form | terminal                  |
| Gender                   | female                    |
| Color contact carrier    | black                     |
| No. of poles             | 4                         |
| PIN 1                    | 13                        |
| PIN 2                    | 23                        |
| PIN 3                    | 33                        |
| PIN 4                    | 43                        |