

MODLINK MSDD FRAME DBL METAL



Nickeled

Frame: metal, matte nickel plated

Lid: metal, matte nickel plated

Link do produto

Ilustração

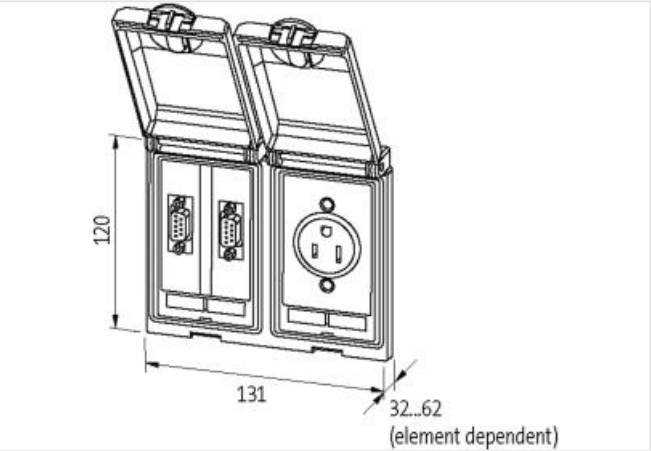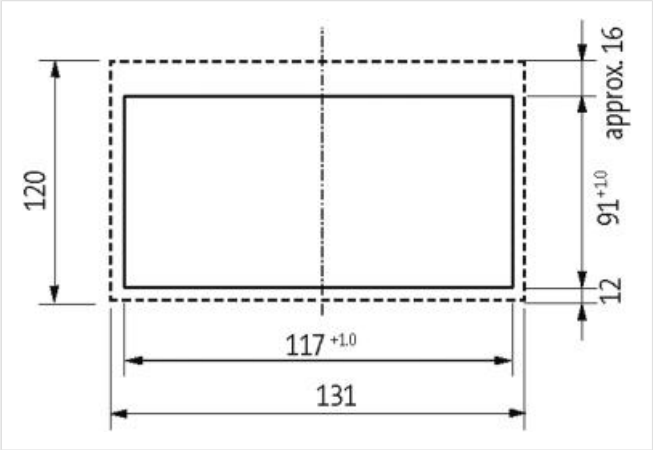

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27189217
ECLASS-6.1	27189260
ECLASS-7.0	27189260
ECLASS-8.0	27189260
ECLASS-9.0	27189260
ECLASS-10.1	27182810
ECLASS-11.1	27182810
ECLASS-12.0	27182810

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado.
A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 04/05/2024

ETIM-5.0	EC002625
Classificação fiscal	85389099
GTIN	4048879035286
Quantidade por embalagem	1
Device protection	
Shielded	yes
Mechanical data Mounting data	
Height	120 mm
Width	130 mm
Depth	35 mm
Frame	
Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-10 °C
Operating temperature max.	60 °C
Storage temperature min.	-25 °C
Storage temperature max.	60 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Coating housing	surface finished
Material housing	Fine zinc die casting