


Modlink MSDD-set: Frame 4000-68512-0000003,  
insert 4000-68000-0940000

Link do produto

Ilustração

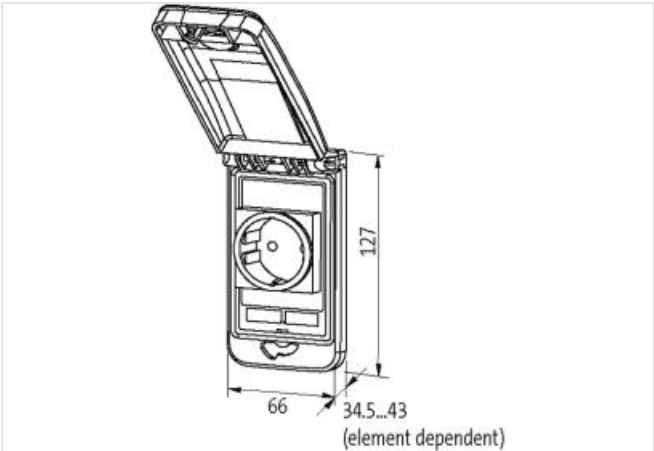

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27189217 |
| ECLASS-6.1       | 27189217 |
| ECLASS-7.0       | 27189217 |
| ECLASS-8.0       | 27189217 |
| ECLASS-9.0       | 27189217 |
| ECLASS-10.1      | 27182806 |
| ECLASS-11.1      | 27182806 |
| ECLASS-12.0      | 27182806 |

|                          |               |
|--------------------------|---------------|
| ETIM-5.0                 | EC002625      |
| Classificação fiscal     | 85366990      |
| GTIN                     | 4048879406741 |
| Quantidade por embalagem | 1             |

**Frame**

|                                               |             |
|-----------------------------------------------|-------------|
| Degree of protection (EN IEC 60529)           | IP65        |
| Operating temperature min.                    | -30 °C      |
| Operating temperature max.                    | 70 °C       |
| Storage temperature min.                      | -30 °C      |
| Storage temperature max.                      | 80 °C       |
| Suitable for installation wall thickness min. | 1 mm        |
| Suitable for installation wall thickness max. | 5 mm        |
| Color cover                                   | transparent |
| Color housing                                 | black       |
| Material lid                                  | PC          |
| Material housing                              | PA          |

**Shielding plate**

|                        |                  |
|------------------------|------------------|
| Connection information | Threaded hole M4 |
| Tightening torque      | 0,9 Nm           |

**USB**

|                                       |                   |
|---------------------------------------|-------------------|
| Operating voltage AC                  | 48 V              |
| Operating voltage DC                  | 48 V              |
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Operating current                     | 1,5 A             |
| USB specification                     | 3.0               |
| Data transmission rate max.           | 5000 MBit/s       |
| Looking techniques                    | Snap-in connector |

**RJ45**

|                                       |                   |
|---------------------------------------|-------------------|
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Current operating max. (UL)           | 175 mA            |
| Family construction form              | RJ45              |
| Family type Back side                 | RJ45              |
| Cable category min.                   | Cat5e             |
| Looking techniques                    | Snap-in connector |