


**Modlink MSDD-set: Frame 4000-68523-0000001,**  
insert 4000-68000-4120000

with touch protection

Link do produto

Ilustração

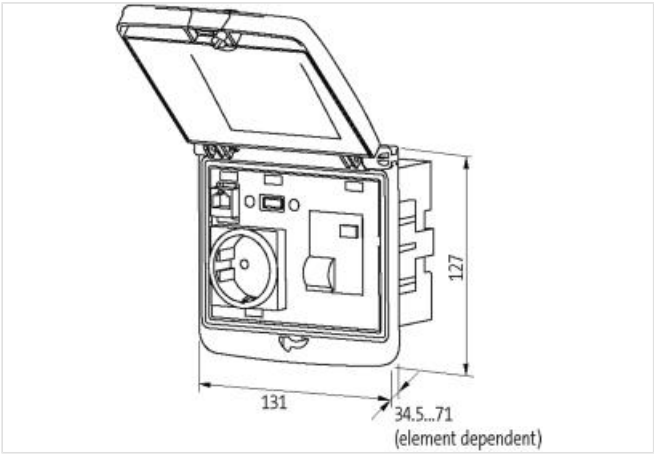

Produto pode diferir da imagem



| Dados comerciais |          |
|------------------|----------|
| ECLASS-6.0       | 27144001 |
| ECLASS-6.1       | 27189217 |
| ECLASS-7.0       | 27189217 |
| ECLASS-8.0       | 27189217 |
| ECLASS-9.0       | 27189217 |
| ECLASS-10.1      | 27182806 |
| ECLASS-11.1      | 27182806 |
| ECLASS-12.0      | 27182806 |

|                                               |                    |
|-----------------------------------------------|--------------------|
| ETIM-5.0                                      | EC002625           |
| Classificação fiscal                          | 85366990           |
| GTIN                                          | 4048879477970      |
| Quantidade por embalagem                      | 1                  |
| <b>Mechanical data   Mounting data</b>        |                    |
| Height                                        | 88 mm              |
| Width                                         | 116 mm             |
| Depth                                         | 72 mm              |
| <b>Frame</b>                                  |                    |
| Degree of protection (EN IEC 60529)           | IP65               |
| Operating temperature min.                    | -30 °C             |
| Operating temperature max.                    | 70 °C              |
| Storage temperature min.                      | -30 °C             |
| Storage temperature max.                      | 80 °C              |
| Suitable for installation wall thickness min. | 1 mm               |
| Suitable for installation wall thickness max. | 5 mm               |
| Color cover                                   | metallic           |
| Color housing                                 | black              |
| Material lid                                  | ABS                |
| Material housing                              | PA                 |
| <b>Fuse</b>                                   |                    |
| Operating voltage AC                          | 250 V              |
| Operating voltage DC                          | 32 V               |
| Nominal current                               | 3 A                |
| <b>USA</b>                                    |                    |
| Connection cross section max.                 | 6 mm <sup>2</sup>  |
| AWG number max.                               | 10                 |
| Operating voltage AC                          | 125 V              |
| Operating current                             | 15 A               |
| Connection                                    | Screw terminals SK |
| No. of poles                                  | 2 + PE             |
| Connections per pole                          | 2                  |
| Protection contact present                    | yes                |
| <b>RJ45</b>                                   |                    |
| Operating voltage AC max. (UL-listed)         | 30 V               |
| Operating voltage DC max. (UL-listed)         | 42,4 V             |
| Current operating max. (UL)                   | 175 mA             |
| Family construction form                      | RJ45               |
| Family type Back side                         | RJ45               |
| Cable category min.                           | Cat5e              |
| Looking techniques                            | Snap-in connector  |