

Modlight Illumix Xtreme Line 27W


LED machine lamp, IP69K, 24VDC, M12 connection

Link do produto

Ilustração



Produto pode diferir da imagem

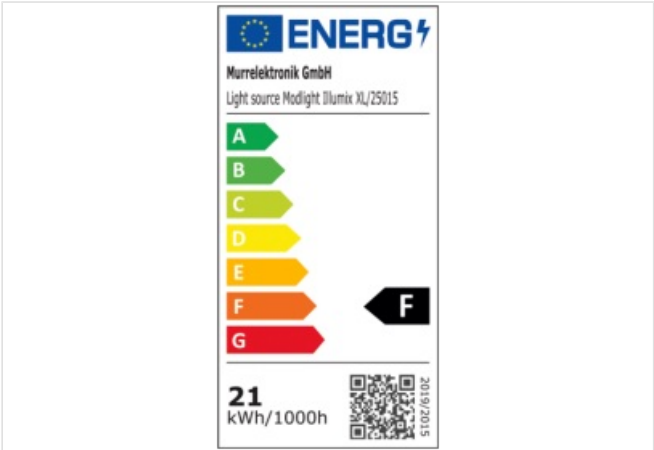

Dados comerciais	
ECLASS-6.0	27110303
ECLASS-6.1	27110390
ECLASS-7.0	27110390
ECLASS-8.0	27110390
ECLASS-9.0	27110345
ECLASS-10.1	27110345
ECLASS-11.1	27110345
ECLASS-12.0	27110345
ETIM-5.0	EC001334
Classificação fiscal	94054239
GTIN	4048879439169
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC	24 V
Current consumption max.	1120 mA
HMI Illumination properties	
Illumination level	860 lx
Installation Connection	
Family construction form	M12
Installation Pin assignment	
No. of poles	5
Device protection Electrical	

Degree of protection (ISO 20653:2013)	IP69K
Additional condition protection degree	inserted, screwed
Mechanical data Material data	
Housing properties	with stainless steel cover
Material housing	Aluminium
Mechanical data Mounting data	
Height	43 mm
Width	97 mm
Depth	441 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	55 °C