

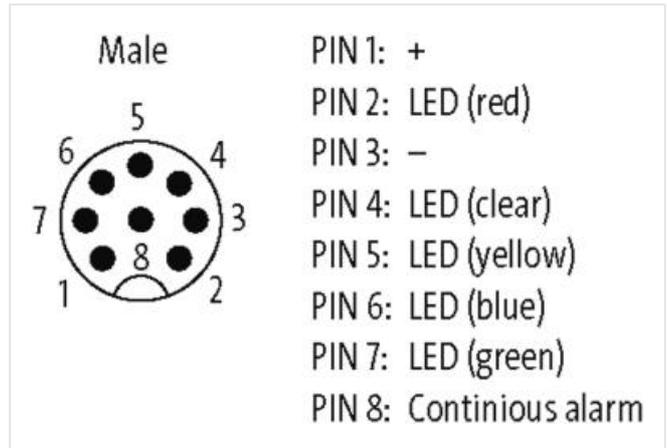
Modlight70 Pro connecting modul 8 pole M12

downward, Input 24VDC

Basic
with M12 connection
Outlet on the bottom
Connection cables are in the online shop under "Connection Technology".

Link do produto**Ilustração**

Produto pode diferir da imagem

**Dados comerciais**

ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
Classificação fiscal	85319000
GTIN	4048879758871
Quantidade por embalagem	1

Electrical data | Supply

Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
-------------------------------------	------

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing black

Material housing Plastic

Mechanical data | Mounting data

Height 140 mm

Width 70 mm

Depth 70 mm

Environmental characteristics | Climatic

Operating temperature min. -30 °C

Operating temperature max. 60 °C

Connection type 1

Mounting method bayonet-locking