


Modlight70 Pro connecting modul 5 pole M12

downward, Input 24VDC

Basic
with M12 connection
Outlet on the bottom
Connection cables are in the online shop under "Connection Technology".

Link do produto

Ilustração

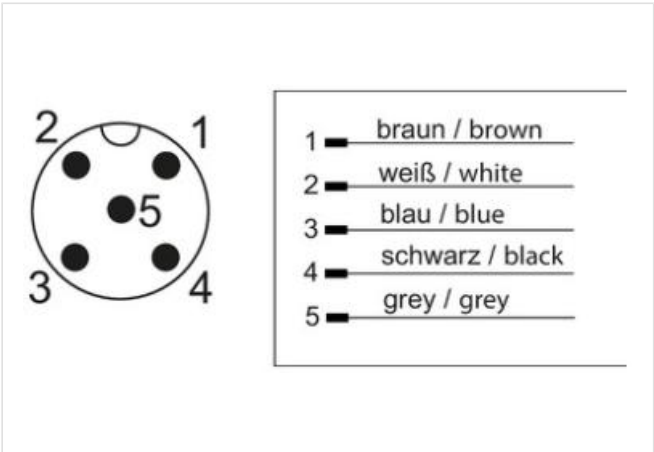

Produto pode diferir da imagem



Dados comerciais	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
Classificação fiscal	85319000
GTIN	4048879758888
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing black

Material housing Plastic

Mechanical data | Mounting data

Height 140 mm

Width 70 mm

Depth 70 mm

Environmental characteristics | Climatic

Operating temperature min. -30 °C

Operating temperature max. 60 °C

Connection type 1

Mounting method bayonet-locking