

Modlight70 Pro connecting modul 8 pole M12

side, Input 24VDC


Basic  
Outlet on the side  
with M12 connection  
Connection cables are in the online shop under "Connection Technology".

Link do produto

Ilustração



Produto pode diferir da imagem

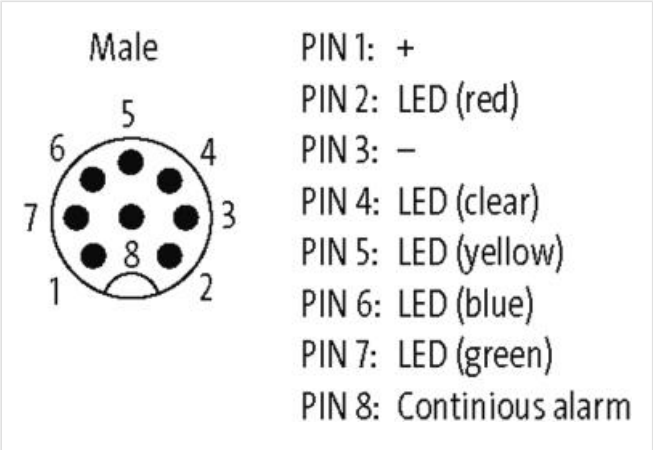

| Dados comerciais                    |               |
|-------------------------------------|---------------|
| ECLASS-6.0                          | 27371232      |
| ECLASS-6.1                          | 27371232      |
| ECLASS-7.0                          | 27371232      |
| ECLASS-8.0                          | 27371232      |
| ECLASS-9.0                          | 27371232      |
| ECLASS-10.1                         | 27371232      |
| ECLASS-11.1                         | 27371232      |
| ECLASS-12.0                         | 27371232      |
| ETIM-5.0                            | EC001152      |
| ETIM-6.0                            | EC001152      |
| ETIM-7.0                            | EC001152      |
| Classificação fiscal                | 85319000      |
| GTIN                                | 4048879758895 |
| Quantidade por embalagem            | 1             |
| Electrical data   Supply            |               |
| Operating voltage DC                | 24 V          |
| Operating voltage DC min.           | 21,6 V        |
| Operating voltage DC max.           | 26,4 V        |
| Device protection   Electrical      |               |
| Degree of protection (EN IEC 60529) | IP65          |

Additional condition protection degree      inserted, locked

**Mechanical data | Material data**

|                  |         |
|------------------|---------|
| Color housing    | black   |
| Material housing | Plastic |

**Mechanical data | Mounting data**

|        |        |
|--------|--------|
| Height | 122 mm |
| Width  | 88 mm  |
| Depth  | 70 mm  |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -30 °C |
| Operating temperature max. | 60 °C  |

**Connection type 2**

|                          |                 |
|--------------------------|-----------------|
| Family construction form | M12             |
| Gender                   | male            |
| Coding                   | A               |
| No. of poles             | 8               |
| PIN 1                    | 24 V DC / 0 V   |
| PIN 2                    | LED-Modul RD    |
| PIN 3                    | 0 V / 24 V DC   |
| PIN 4                    | LED-Modul CL    |
| PIN 5                    | LED-Modul YE    |
| PIN 6                    | LED-Modul BU    |
| PIN 7                    | LED-Modul GN    |
| PIN 8                    | Buzzer          |
| Mounting method          | bayonet-locking |