

Signal tower Modlight70 Pro equipped with LED modules

green,amber,red,buzzer,M12 plug downward


Basic, buzzer, flash + LED modules + M12 (down)
green, yellow, red

Link do produto

Ilustração



Produto pode diferir da imagem

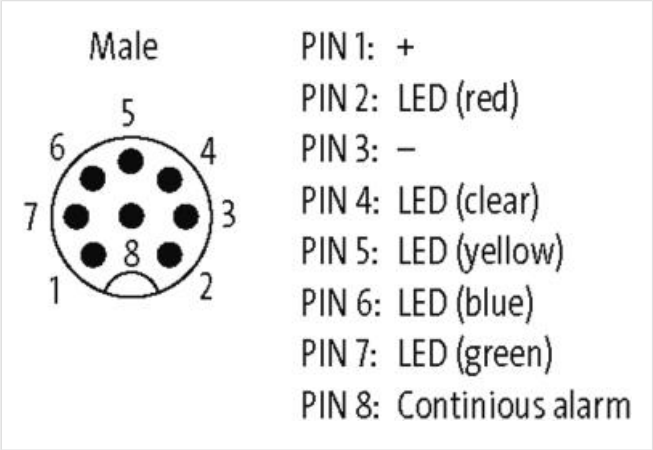

Dados comerciais	
ECLASS-6.0	27371230
ECLASS-6.1	27371230
ECLASS-7.0	27371230
ECLASS-8.0	27371230
ECLASS-9.0	27371230
ECLASS-10.1	27371230
ECLASS-11.1	27371230
ECLASS-12.0	27371230
ETIM-5.0	EC001042
Classificação fiscal	85318070
GTIN	4048879759939
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Current consumption max.	385 mA
Industrial communication HMI	
Buzzer sound	fast beep, continuous beep, fast high-low, sweep tone
Reduced sound pressure at 1 m	80 dB
Sound pressure at 1 m	90 dB
HMI Illumination properties	

Blink cycles	60 ±12 per minute
--------------	-------------------

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height	293 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C