

**SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE**

24V LED+Z-Diode PG9

Form B (10 mm)

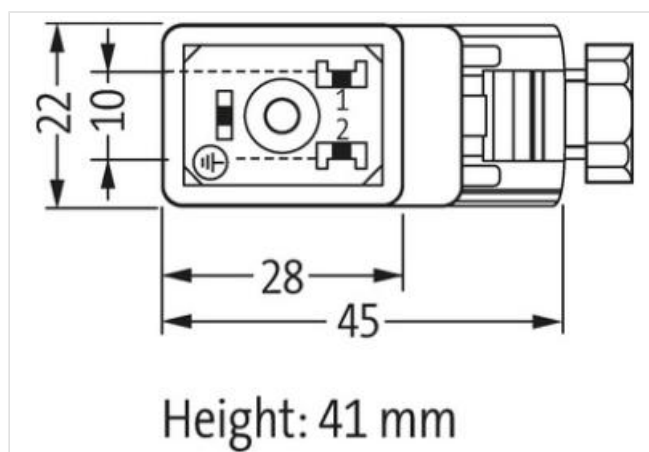
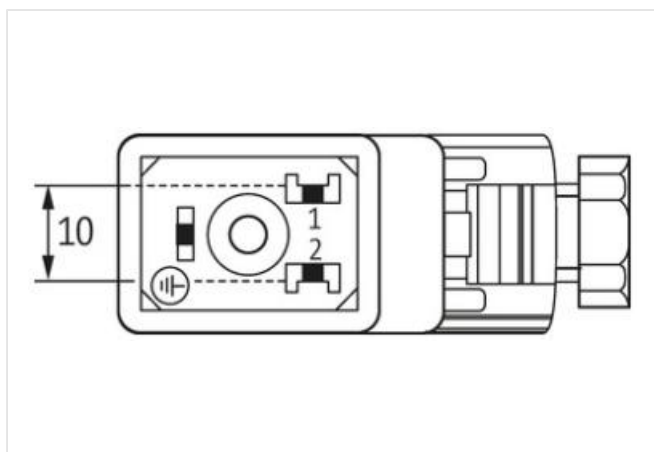
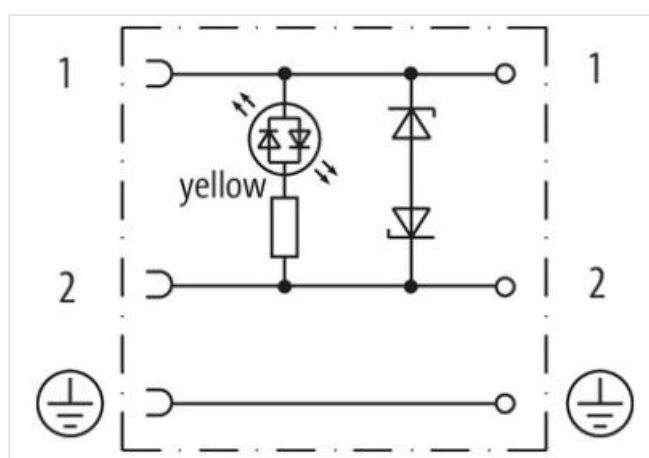
24 V AC  $\pm 20\%$  / DC  $\pm 25\%$ 

LED and Z-diode

PG9

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link do produto](#)
**Ilustração**


Produto pode diferir da imagem


**Side 1**

Degree of protection (EN IEC 60529)

IP65

**Dados comerciais**

ECLASS-6.0

27279221

ECLASS-7.0

27440104

|                                                 |                                                                                                                                                       |
|-------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------|
| ECLASS-8.0                                      | 27440104                                                                                                                                              |
| ECLASS-9.0                                      | 27440102                                                                                                                                              |
| ECLASS-10.1                                     | 27440105                                                                                                                                              |
| ECLASS-11.1                                     | 27440105                                                                                                                                              |
| ECLASS-12.0                                     | 27440105                                                                                                                                              |
| ETIM-5.0                                        | EC002062                                                                                                                                              |
| Classificação fiscal                            | 85366990                                                                                                                                              |
| GTIN                                            | 4048879187336                                                                                                                                         |
| Quantidade por embalagem                        | 1                                                                                                                                                     |
| <b>Electrical data   Supply</b>                 |                                                                                                                                                       |
| Operating voltage AC                            | 24 V                                                                                                                                                  |
| Operating voltage DC                            | 24 V                                                                                                                                                  |
| Current operating per contact max.              | 4 A                                                                                                                                                   |
| <b>Diagnostics</b>                              |                                                                                                                                                       |
| Status indication LED                           | yellow                                                                                                                                                |
| <b>Installation   Connection</b>                |                                                                                                                                                       |
| Tightening torque                               | 0,4 Nm                                                                                                                                                |
| Mounting set                                    | M3                                                                                                                                                    |
| <b>Installation   Pin assignment</b>            |                                                                                                                                                       |
| No. of poles                                    | 2 + PE                                                                                                                                                |
| <b>Device protection   Electrical</b>           |                                                                                                                                                       |
| Additional condition protection degree          | inserted, screwed                                                                                                                                     |
| Additional suppressor                           | Z-Diode                                                                                                                                               |
| <b>Mechanical data   Mounting data</b>          |                                                                                                                                                       |
| Mounting method                                 | inserted, screwed                                                                                                                                     |
| Clamping range min.                             | 5 mm                                                                                                                                                  |
| Clamping range max.                             | 9,5 mm                                                                                                                                                |
| <b>Environmental characteristics   Climatic</b> |                                                                                                                                                       |
| Operating temperature min.                      | -20 °C                                                                                                                                                |
| Operating temperature max.                      | 60 °C                                                                                                                                                 |
| <b>Important installation notes</b>             |                                                                                                                                                       |
| Note on strain relief                           | Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.                                                   |
| Note on bending radius                          | <b>Attention:</b> Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces. |