


M12 MV insert shielded male / female snap


Insert - stationary housing
Male straight – female straight
M12, 5-pole
A-coded
Good chemical and oil resistance (oil resistance does not apply to use with PVC cable)
The resistance to aggressive media should be individually tested for your application. Further details on request.


Link do produto

Ilustração

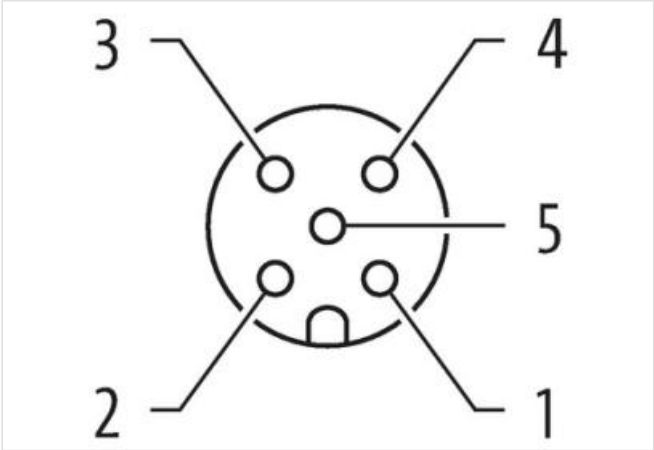

1		○ 1
2		○ 2
3		○ 3
4		○ 4
5		○ 5

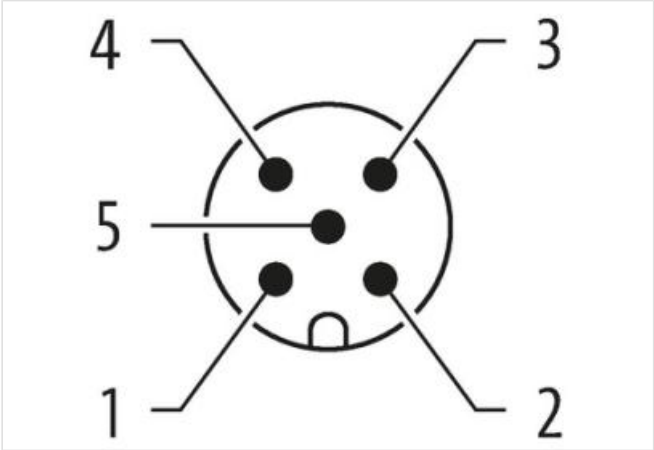

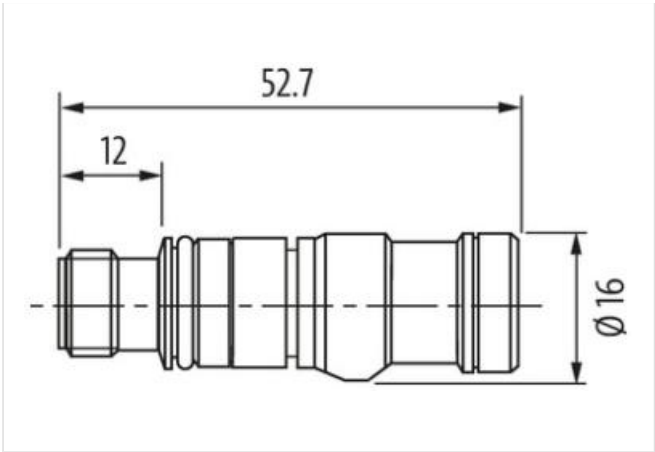

Produto pode diferir da imagem

Side 1	
Family construction form	M12
Coding	A
Side 2	
Family construction form	M12
Coding	A
Dados comerciais	
ECLASS-6.0	27260702
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC001855
Classificação fiscal	85366990
GTIN	4048879562805
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC	49 V
Operating voltage DC	49 V
Current operating per contact max.	4 A
Installation Connection	
Tightening torque	0,6 Nm
Mounting set	M12 x 1
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Additional condition protection degree	inserted, screwed
Rated surge voltage	1,5 kV
Mechanical data Material data	
Coating housing	nickel plated
Material gasket	FKM
Material housing	Brass
Mechanical data Mounting data	
Mounting method	inserted, screwed, Shaking protection

As informações contidas nesta folha de dados foram elaboradas com o máximo cuidado.
A falta de integridade, exatidão e atualização das informações é considerada negligência grave. versão: 01/05/2024

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	85 °C