




T-Coupler M12 male/ M12 male w.cable+female A-cod.

4-pol. / 2-pol. + 8-pol.

AIDA conform
T-coupler (Slim Line)
Male straight – female/male straight
M12 – M12, 4-pole
Connection cable 0.2 m
Distribution function (NO)
for 8-pole units
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link do produto

Ilustração

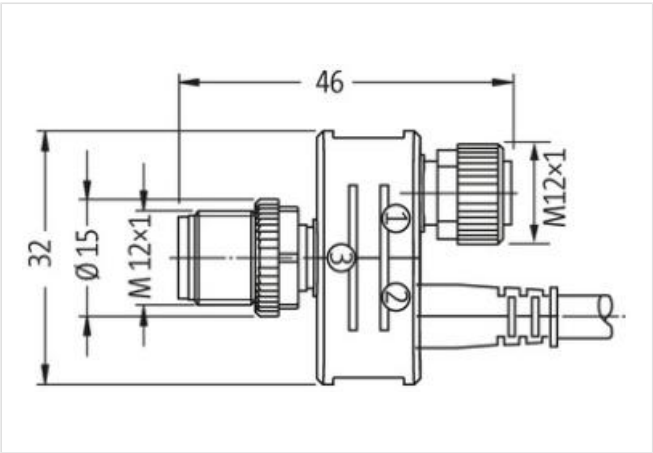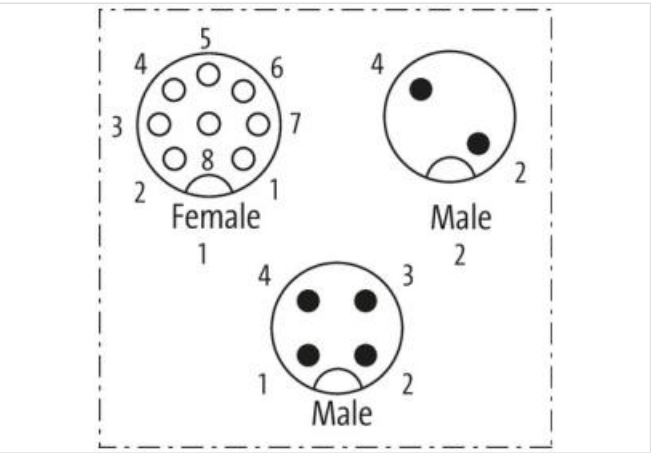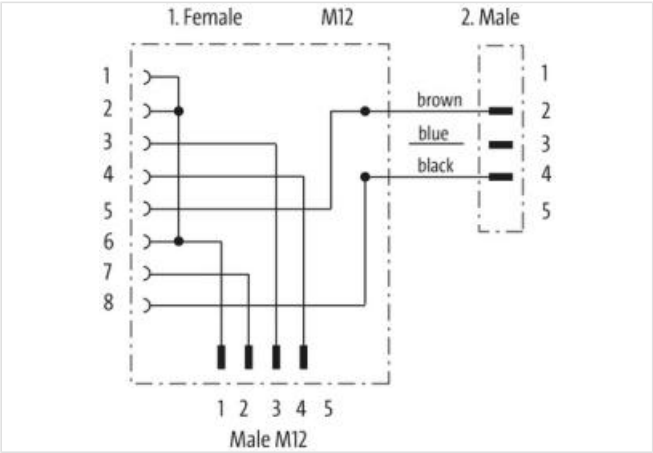

Produto pode diferir da imagem

Dados comerciais	
ECLASS-6.0	27279218
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106

ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC002062
Classificação fiscal	85444290
GTIN	4048879560351
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C
Important installation notes	
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.