


A3 male 3-pole, Push-in, 400 V, 10 A

A3  
Male  
3-pole  
Push-In terminals  
Technical data will be only guaranteed with Murrelektronik components.  
Please use wire end ferrule.

Link do produto

Ilustração

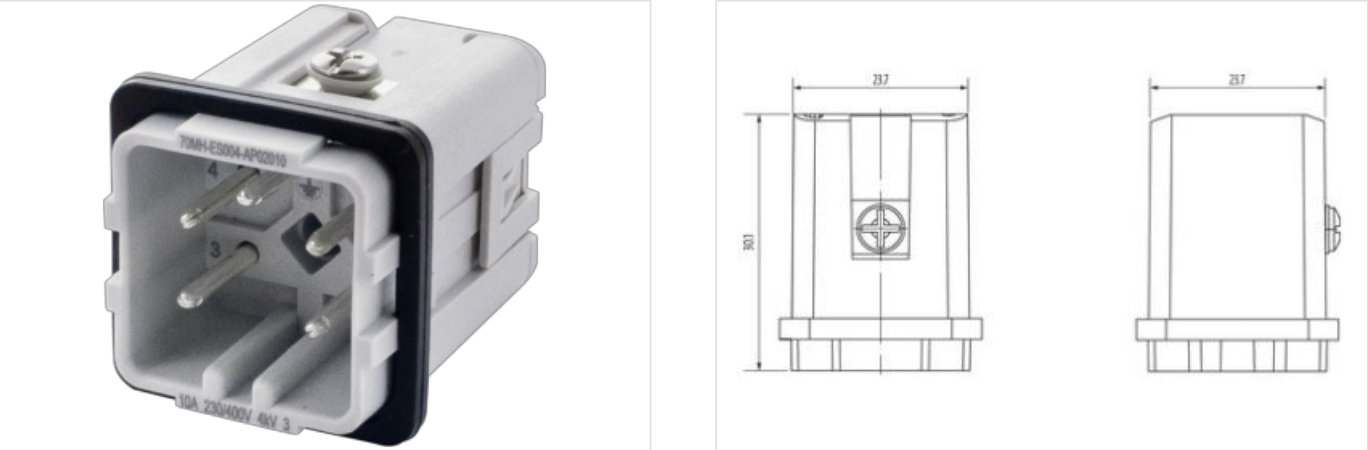

Produto pode diferir da imagem



| Dados comerciais                             |               |
|----------------------------------------------|---------------|
| ECLASS-6.0                                   | 27143424      |
| ECLASS-6.1                                   | 27261204      |
| ECLASS-7.0                                   | 27440205      |
| ECLASS-8.0                                   | 27440205      |
| ECLASS-9.0                                   | 27440205      |
| ECLASS-10.1                                  | 27440205      |
| ECLASS-11.1                                  | 27440205      |
| ECLASS-12.0                                  | 27440205      |
| ETIM-5.0                                     | EC000438      |
| Classificação fiscal                         | 85366990      |
| GTIN                                         | 4048879764193 |
| Quantidade por embalagem                     | 1             |
| Electrical data   Supply                     |               |
| Operating voltage AC per power contact max.  | 400 V         |
| Operating voltage AC per signal contact max. | 230 V         |
| Operating voltage DC per power contact max.  | 400 V         |
| Operating voltage DC per signal contact max. | 230 V         |
| Operating current                            | 10 A          |
| Installation                                 |               |
| Connection cross section min.                | 0,14 mm²      |

|                               |                     |
|-------------------------------|---------------------|
| Connection cross section max. | 1,5 mm <sup>2</sup> |
|-------------------------------|---------------------|

**Installation | Connection**

|                    |                                |
|--------------------|--------------------------------|
| Stripping length   | 10 mm                          |
| Connection         | Push-In spring clamp terminals |
| Gender             | male                           |
| Mating cycles min. | 500                            |

**Installation | Pin assignment**

|              |        |
|--------------|--------|
| No. of poles | 3 + PE |
|--------------|--------|

**Device protection | Electrical**

|                                   |      |
|-----------------------------------|------|
| Pollution Degree                  | 3    |
| Rated surge voltage               | 4 kV |
| Overvoltage category (EN 60950-1) | III  |

**Mechanical data | Material data**

|                             |               |
|-----------------------------|---------------|
| Coating contact             | silver-plated |
| Combustibility class (UL94) | V-0           |
| Material contact carrier    | PC            |

**Mechanical data | Mounting data**

|        |         |
|--------|---------|
| Size   | A3      |
| Height | 30,1 mm |
| Width  | 23,7 mm |
| Depth  | 23,7 mm |

**Environmental characteristics | Climatic**

|                                    |           |
|------------------------------------|-----------|
| Operating temperature min.         | -40 °C    |
| Operating temperature max.         | 125 °C    |
| Climatic category (EN IEC 60068-1) | 40/125/21 |