

A3 male 4-pole, Push-in, 400 V, 10 A


A3
Male
4-pole
Push-In terminals
Technical data will be only guaranteed with Murrelektronik components.
Please use wire end ferrule.

Link do produto

Ilustração



Produto pode diferir da imagem

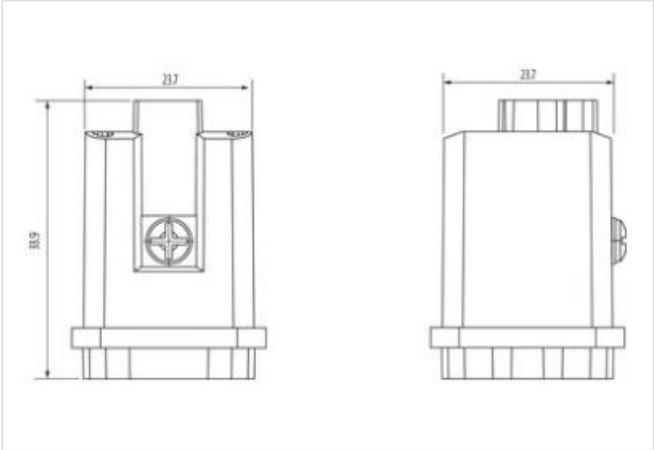

Dados comerciais	
ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440205
ECLASS-8.0	27440205
ECLASS-9.0	27440205
ECLASS-10.1	27440205
ECLASS-11.1	27440205
ECLASS-12.0	27440205
ETIM-5.0	EC000438
Classificação fiscal	85366990
GTIN	4048879764513
Quantidade por embalagem	1
Electrical data Supply	
Operating voltage AC per power contact max.	400 V
Operating voltage AC per signal contact max.	230 V
Operating voltage DC per power contact max.	400 V
Operating voltage DC per signal contact max.	230 V
Operating current	10 A
Installation	
Connection cross section min.	0,14 mm²

Connection cross section max.	1,5 mm ²
-------------------------------	---------------------

Installation | Connection

Stripping length	10 mm
Connection	Push-In spring clamp terminals
Gender	male
Mating cycles min.	500

Installation | Pin assignment

No. of poles	4 + PE
--------------	--------

Device protection | Electrical

Pollution Degree	3
Rated surge voltage	4 kV
Overvoltage category (EN 60950-1)	III

Mechanical data | Material data

Coating contact	silver-plated
Combustibility class (UL94)	V-0
Material contact carrier	PC

Mechanical data | Mounting data

Size	A3
Height	33,9 mm
Width	23,7 mm
Depth	23,7 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/21