

A3 Bulkhead mounted h., IP67

Single locking lever m.


A3
Bulkhead mounted housing
Single locking lever
IP67
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração



Produto pode diferir da imagem

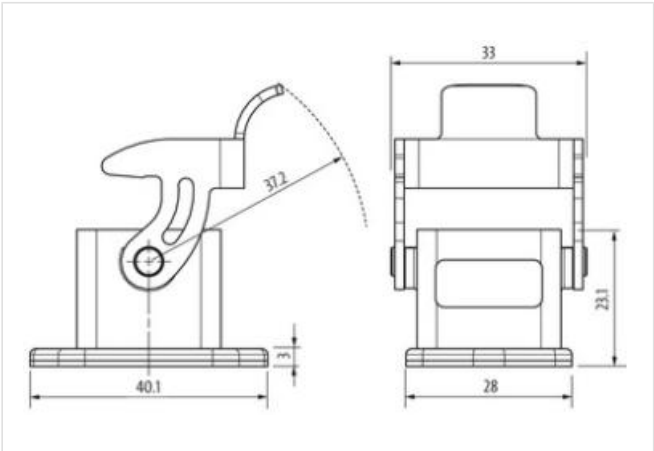

Dados comerciais

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
Classificação fiscal	85389099
GTIN	4048879643016
Quantidade por embalagem	1

Installation | Connection

Mating cycles min.	500
--------------------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	inserted, locked

Mechanical data

Housing type	Bulkhead mounted housing
--------------	--------------------------

Mechanical data | Material data

Coating housing	powder-coated
Coating locking	verzinkt
Material gasket	NBR

Material housing	Zinc die-casting
Locking material	Steel
Mechanical data Mounting data	
Size	A3
Height	23,1 mm
Width	40,1 mm
Depth	33 mm
Looking techniques	Single locking lever
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	100 °C
Climatic category (EN IEC 60068-1)	40/100/21