


B6 Bulkhead mounted h., IP65

Single locking lever m.

B6  
Bulkhead mounted housing  
Single locking lever  
IP65  
Technical data will be only guaranteed with Murrelektronik components.

Link do produto

Ilustração

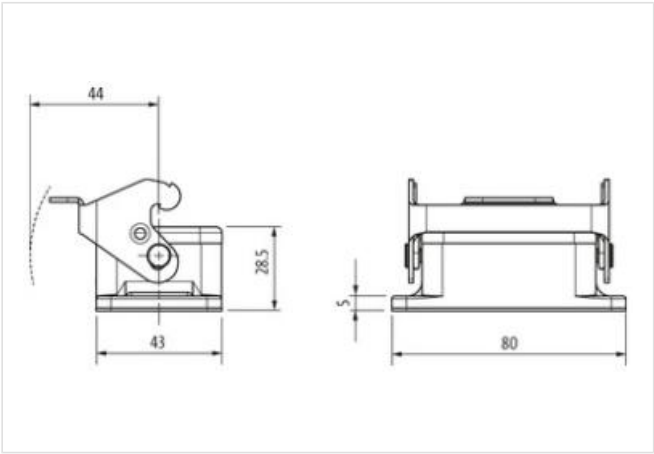

Produto pode diferir da imagem

| Dados comerciais                       |                                         |
|----------------------------------------|-----------------------------------------|
| ECLASS-6.0                             | 27143424                                |
| ECLASS-6.1                             | 27261203                                |
| ECLASS-7.0                             | 27440202                                |
| ECLASS-8.0                             | 27440202                                |
| ECLASS-9.0                             | 27440202                                |
| ECLASS-10.1                            | 27440202                                |
| ECLASS-11.1                            | 27440202                                |
| ECLASS-12.0                            | 27440202                                |
| ETIM-5.0                               | EC000437                                |
| Classificação fiscal                   | 85389099                                |
| GTIN                                   | 4048879644044                           |
| Quantidade por embalagem               | 1                                       |
| Installation   Connection              |                                         |
| Mating cycles min.                     | 500                                     |
| Device protection   Electrical         |                                         |
| Degree of protection (EN IEC 60529)    | IP65                                    |
| Additional condition protection degree | inserted, locked, with screw connection |
| Mechanical data                        |                                         |
| Housing type                           | Bulkhead mounted housing                |
| Mechanical data   Material data        |                                         |
| Coating housing                        | powder-coated                           |
| Coating locking                        | verzinkt                                |
| Material gasket                        | NBR                                     |

|                  |                      |
|------------------|----------------------|
| Material housing | Aluminum die casting |
|------------------|----------------------|

|                  |       |
|------------------|-------|
| Locking material | Steel |
|------------------|-------|

**Mechanical data | Mounting data**

|      |    |
|------|----|
| Size | B6 |
|------|----|

|        |         |
|--------|---------|
| Height | 28,5 mm |
|--------|---------|

|       |       |
|-------|-------|
| Width | 43 mm |
|-------|-------|

|       |       |
|-------|-------|
| Depth | 80 mm |
|-------|-------|

|                    |                      |
|--------------------|----------------------|
| Looking techniques | Single locking lever |
|--------------------|----------------------|

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
|----------------------------|--------|

|                            |        |
|----------------------------|--------|
| Operating temperature max. | 100 °C |
|----------------------------|--------|

|                                    |           |
|------------------------------------|-----------|
| Climatic category (EN IEC 60068-1) | 40/100/21 |
|------------------------------------|-----------|